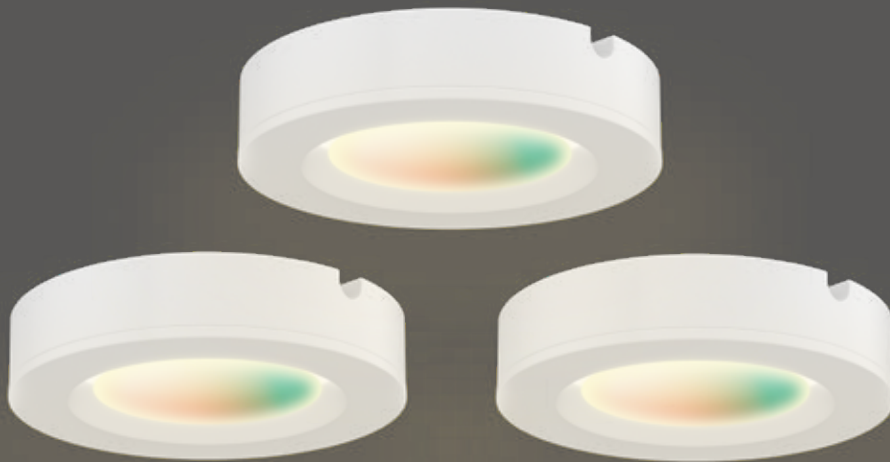

WiFi smart puck

Enhancing your decor is made easy with our WiFi RGB + CCT adjustable pucks. These efficiently designed fixtures allow for tremendous flexibility and an infinite spectrum of vibrant colors. Easily control and manage your lighting remotely with the Dals app connected to your mobile device or through your preferred AI home assistant.



Model	Size	Watts	Delivered lumens	CRI	Color °T	Voltage
SWPK1-RGBCCT	1 x Ø2.75"	2.3 W	100 lm	80+	RGB + 2700 K - 6500 K	12 V
SWPK3-RGBCCT	3 x Ø2.75"	7 W	300 lm	80+	RGB + 2700 K - 6500 K	12 V
SWPK5-RGBCCT	5 x Ø2.75"	10 W	500 lm	80+	RGB + 2700 K - 6500 K	12 V

Specifications

WiFi - no hub needed
 Excellent color rendering
 Full color spectrum
 2700K - 6500K in pure whites
 Superior LED performance and lifespan
 Minimal heat emission
 Suitable for enclosed fixtures
 Dimmable through the Dals app or supplied infrared remote
 Over 50,000 hours of service life
 Create groups
 Set schedules
 Remote access
 Compatible with Google Assistant and Amazon Alexa
 Remote control included in kits of 3 and 5 pucks

*Note:

Plug-in or hard-wired power supply required for installation when purchasing the single unit (SWPK1-RGBCCT). Sold separately.

Power supplies: plug-in

ETR-LED10WPI
 12VDC/10W class 2 LED driver

ETR-LED24WPI
 12VDC/24W class 2 LED driver

Power supplies: hard-wired

BT06DIMLED-IC
 6W dimmable LED hardwire driver

BT12DIMLED-IC
 12W dimmable LED hardwire driver

BT24DIMLED-IC
 24W dimmable LED hardwire driver

BT36DIMLED
 36W dimmable LED hardwire driver

BT48DIMLED
 48W dimmable LED hardwire driver

Accessories

SWPK-ACC-EXT24
 24" extension cord

SWPK-ACC-EXT60
 60" extension cord

Order example

SWPK3-RGBCCT
 3 x RGB+CCT puck set that includes a WiFi-enabled controller which you can control with your smartphone or the infrared remote supplied with the kit

Download the free Dals app



SWPKX-RGBCCT

