



# nVent CADDY All-in-One Stud-Mounted Without Mud Ring – A1SF0GTC

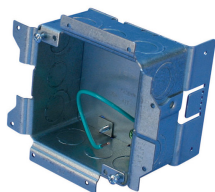

- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Includes multiple knockouts on each side of the box
- Assemblies keyed for precise alignment when installed on both sides of a stud
- Works with standard US and Canadian mud rings

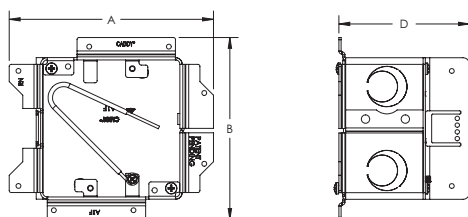

Part Number	A1SF0GTC
Material	Steel
Finish	Pregalvanized
Knockout Sizes	(8) 1/2", 3/4" (3) 1/2"
Ground Wire Included	Yes
Back Plate Pre-assembled	Yes
Box Volume	32.8 in <sup>3</sup>
Depth [D]	3 5/8"
A	5 3/4"
B	5 1/8"
Certifications	cULus
Standard Packaging Quantity	20 pc
UPC	78285679487

Ground wire pigtail is 10".

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

