



## RATCHET KITS AND MANUAL SETS

New and improved high-leverage wrench with five-degree ratcheting mechanism provides versatility and accessibility in tight spaces. The long, over-mold handle offers greater leverage, comfort and grip. Punch 1/2" to 2" conduit size holes in 10-gauge mild steel; also punches aluminum, brass, copper, fiberglass and plastics.



### RATCHET WRENCH KITS

CAT. NO.	UPC NO.	DESCRIPTION
7238SB	783310347576	Slug-Buster® 1/2" to 2"
7240SB	783310028604	Slug-Buster® 1/2", 3/4" Conduit, 30.5mm

New High-Leverage Ratchet Wrench

### MANUAL KNOCKOUT SETS


CAT. NO.	UPC NO.	DESCRIPTION
7237BB	783310320142	Slug-Buster® 1-1/2" to 2" Conduit
737BB	783310199748	Standard Round 1-1/2" to 2" Conduit
7235BB	783310320135	Slug-Buster® 1/2" to 1-1/4" Conduit
735BB	783310199731	Standard Round 1/2" to 1-1/4" Conduit



### MANUAL DRAW STUDS

CAT. NO.	UPC NO.	DESCRIPTION
DSBB-7/16	783310090601	7/16" Manual Draw Stud for 1/2" Conduit Size Knockouts
DSBB-3/4	783310090625	3/4" Manual Draw Stud for 3/4" to 2" Conduit Size Knockouts
DSBB-1-1/8	783310090687	1-1/8" Manual Draw Stud for 2-1/2" to 4" Conduit Size Knockouts. Use with 3036AVBB Ball-Bearing Nut

# KNOCKOUT SETS AND INDIVIDUAL PARTS

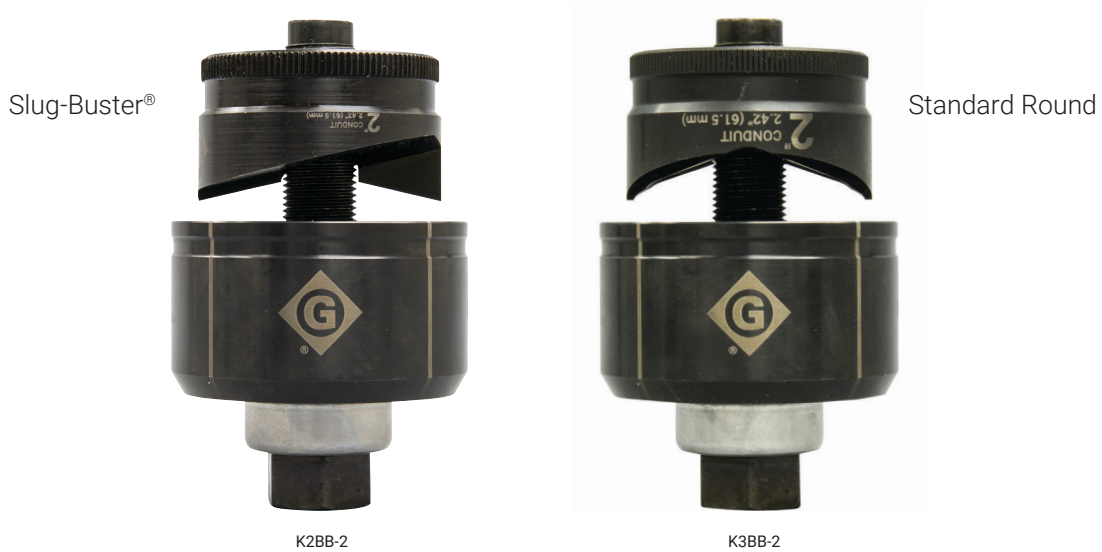

HOLE SIZE			SLUG-BUSTER®		STANDARD ROUND			DIE	MANUAL DRAW STUD	HYDRAULIC DRAW STUD
CONDUIT SIZE	ACTUAL SIZE		SET	PUNCH	SET	PUNCH				
1/2"	0.89"	22.5 mm	K2BB-1/2	K2P-1/2	K3BB-1/2	K3P-1/2	KD-1/2	DSBB-7/16	DSH-7/16, DSH-S7/16	
3/4"	1.12"	28.3 mm	K2BB-3/4	K2P-3/4	K3BB-3/4	K3P-3/4	KD-3/4	DSBB-3/4	DSH-3/4, DSH-S3/4	
-	-	30.5 mm	K2BBM-0305	K2PM-0305	-	-	KDM-0305			
1"	1.36"	34.6 mm	K2BB-1	K2P-1	K3BB-1	K3P-1	KD-1			
1-1/4"	1.70"	43.2 mm	K2BB-1-1/4	K2P-1-1/4	K3BB-1-1/4	K3P-1-1/4	KD-1-1/4			
1-1/2"	1.95"	49.6 mm	K2BB-1-1/2	K2P-1-1/2	K3BB-1-1/2	K3P-1-1/2	KD-1-1/2			
2"	2.42"	61.5 mm	K2BB-2	K2P-2	K3BB-2	K3P-2	KD-2	DSBB-1-1/8 and 3036AVBB	DSH-1-1/8	
2-1/2"	2.91"	74.0 mm	-	-	K3BB-2-1/2	K3P-2-1/2	KD-2-1/2			
3"	3.54"	89.9 mm	-	-	K3BB-3	K3P-3	KD-3			
3-1/2"	4.04"	102.7 mm	-	-	K3BB-3-1/2	K3P-3-1/2	KD-3-1/2	DSBB-1-1/8, 3037AV, and 3036AVBB	DSH-1-1/8	
4"	4.54"	115.4 mm	-	-	K3BB-4	K3P-4	KD-4			

## CATALOG NUMBER KEY

### Part Type

K2 = Slug-Buster® Punch

K3 = Standard Round Punch

KD = Knockout Die

DS = Draw Stud

### Tool Usage

BB = Manual Ball Bearing

H = Hydraulic

### Size Type

Default = Conduit (in)

M = Metric (mm)