

## 6" LED Closet Light with Motion Sensor

Wet Location






 
**DESCRIPTION**

6" Multi-Purpose Surface Mounted Energy-Efficient Fixture That Is Extremely Convenient For Lighting All Your Secondary Spaces. Motion Activated Occupancy Sensor Activates Light When Motion Is Detected And Turns It Off 30 Seconds After Room Is Vacated.

**FEATURES & BENEFITS**

Fast & Easy to Install in J-Box - Save on Labor  
 Wet Location - Suitable For Closets, Storages, Utility Rooms, Soffits  
 CRI 90+ for True Color Rendering

**DIMENSIONS** OD 8" Thickness 1 3/8"

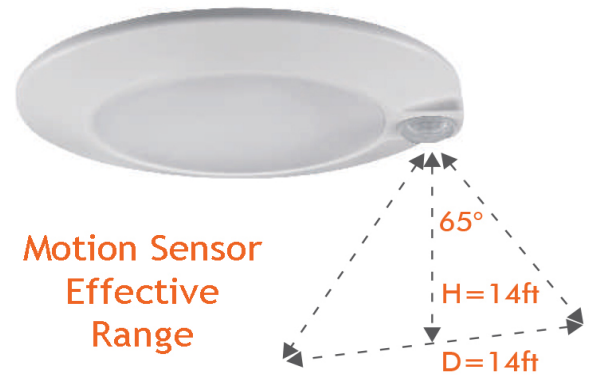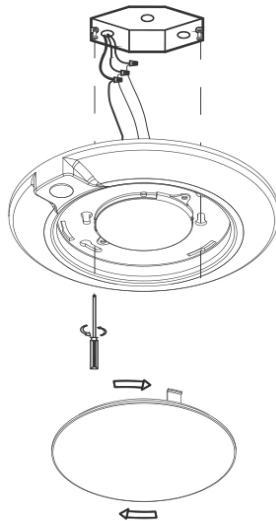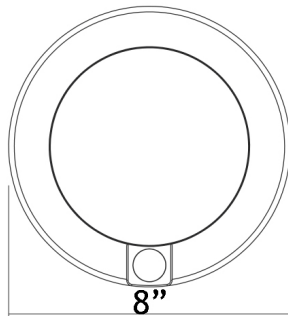

Project: \_\_\_\_\_

Location: \_\_\_\_\_

Trim: \_\_\_\_\_ Qty: \_\_\_\_\_

Notes: \_\_\_\_\_

| SPECIFICATION         |                                                   |
|-----------------------|---------------------------------------------------|
| Applications          | Closets, Storages, Utility Rooms, Attics, Soffits |
| Energy Used           | 15 W                                              |
| Color Temperature (K) | 3000                                              |
| Light Output (lm)     | 900                                               |
| Halogen Equivalent    | 75 W                                              |
| Beam Angle            | 120°                                              |
| CRI                   | 90 +                                              |
| Driver Input          | 120V AC 50/60 Hz                                  |
| Dimming               | Not Dimmable                                      |
| Approved Location     | Wet Locations                                     |
| Air Tight             | No                                                |
| Ambient Temperature   | -4° F (-20° C) to +104° F (+40° C)                |
| Projected Life        | 70% Light Output at 50,000 Hours                  |
| Certification         | cETLus                                            |
| Warranty              | 5 Year                                            |

**ORDERING GUIDE**

|         | CCT  | Trim |
|---------|------|------|
| CSC3025 | - xK | xx   |

Stock model 30K White Trim: **CSC3025-3K-WH**

4000K & 5000K and Black, Bronze & Brushed Nickel Trims Available by Custom Order