



# A-Shape LED

## 8.8A19/PER/927/P/E26/DIM 6/1FB T20

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


### Product data

| General Information                   |                                    |
|---------------------------------------|------------------------------------|
| Base                                  | E26 [ Single Contact Medium Screw] |
| Nominal Lifetime (Nom)                | 15000 h                            |
| Switching Cycle                       | 50000X                             |
| Technical Type                        | 8.8-60W                            |
| Light Technical                       |                                    |
| Color Code                            | 927                                |
| Beam Angle (Nom)                      | 250 °                              |
| Initial lumen (Nom)                   | 800 lm                             |
| Luminous Flux (Rated) (Nom)           | 800 lm                             |
| Color Designation                     | Warm White (WW)                    |
| Correlated Color Temperature (Nom)    | 2700 K                             |
| Luminous Efficacy (rated) (Nom)       | 90.00 lm/W                         |
| Color Consistency                     | <4                                 |
| Color Rendering Index (Nom)           | 90                                 |
| LLMF At End Of Nominal Lifetime (Nom) | 70 %                               |
| Operating and Electrical              |                                    |
| Input Frequency                       | 60 Hz                              |
| Power (Rated) (Nom)                   | 8.8 W                              |
| Lamp Current (Nom)                    | 80 mA                              |
| Wattage Equivalent                    | 60 W                               |
| Starting Time (Nom)                   | 0.5 s                              |

| Warm Up Time to 60% Light (Nom) | 0.5 s                              |
|---------------------------------|------------------------------------|
| Power Factor (Nom)              | 0.7                                |
| Voltage (Nom)                   | 120 V                              |
| Temperature                     |                                    |
| T-Case Maximum (Nom)            | 90 °C                              |
| Controls and Dimming            |                                    |
| Dimmable                        | Yes                                |
| Mechanical and Housing          |                                    |
| Bulb Finish                     | Frosted                            |
| Product Data                    |                                    |
| Order product name              | 8.8A19/PER/927/P/E26/DIM 6/1FB T20 |
| EAN/UPC - Product               | 046677550431                       |
| Order code                      | 550434                             |
| Numerator - Quantity Per Pack   | 1                                  |
| Numerator - Packs per outer box | 6                                  |
| Material Nr. (12NC)             | 929002036104                       |
| Net Weight (Piece)              | 0.060 kg                           |

# A-Shape LED


## Dimensional drawing

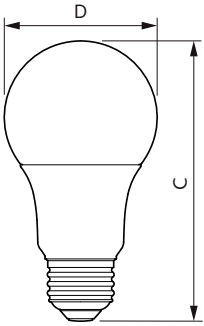


Bulb A19 120V 8.8-60W 800lm 2700K E26 D

| Product                            | D       | C        |
|------------------------------------|---------|----------|
| 8.8A19/PER/927/P/E26/DIM 6/1FB T20 | 62.5 mm | 111.5 mm |


## Photometric data

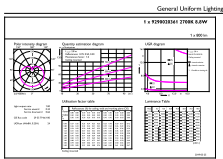

60W E26 A19 927 Frosted

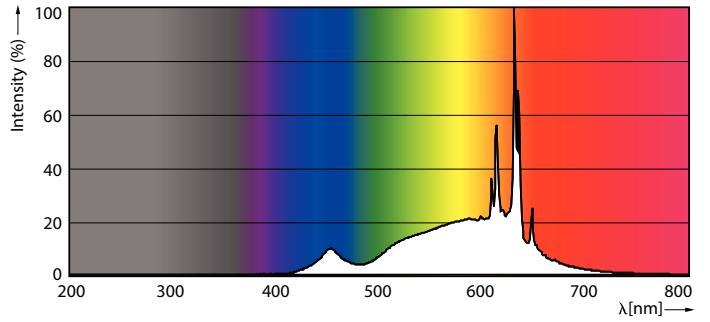


60W E26 A19 927 Frosted

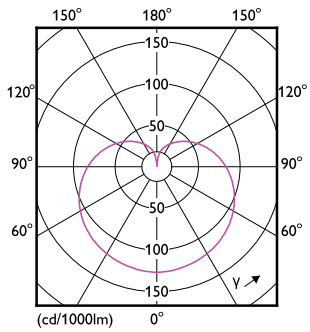

40 60 75 100W E26 A19 A21 Frosted

# A-Shape LED

## Lifetime

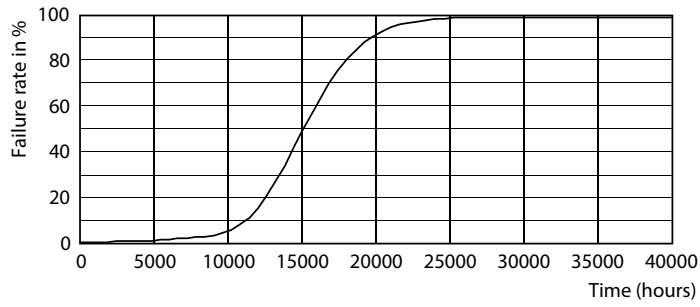

LEDbulb\_15K LED

LEDbulb\_15K LMP

