

# Color-Keyed®

## Narrow-Tongue Copper Lug

T&B Catalog Number:



54261NT0410

UPC Number:

78620991217


Status:

Active

Description:

Copper Two-Hole Lug - Standard Barrel Narrow Tongue Lug - max 35KV, 2/0 AWG Wire, 1/4" Bolt Size, 5/8" Spacing, Tin Plated with Inspection Hole, Black 45

### General

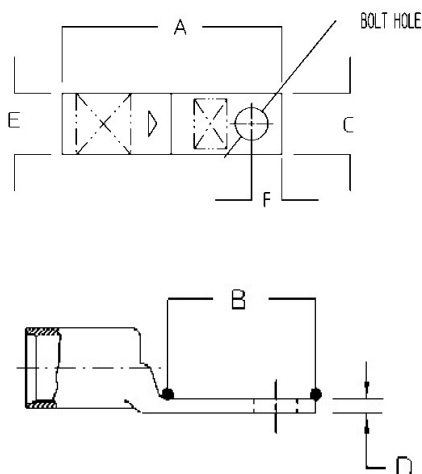

Material	Copper
Finish	Tin Plated
Wire Size	2/0 AWG
Number of Studs	2
Stud Size	1/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Narrow
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	45

### Dimension Information

A (inches)	2.660
B (inches)	1.660
C (inches)	0.571
D (inches)	0.140
E (inches)	0.571
F (inches)	0.380
H (inches)	0.630

### Specifications

Voltage Rating	600V
----------------	------

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	7.3 lbs. per 100

### Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)