

## Long Barrel Copper Lug T&B Catalog Number:

54816BEPH

**UPC Number:**

78621024320

**Status:**

Active

**Description:**

Copper Two-Hole Lug, Long Barrel, Peep Hole, Max 35kV, Wire Size 3/0 AWG, 3/8 Inch Bolt Size, 1 Inch Hole Spacing, Tin Plated, Die Code 50, Die Color Code Orange

### General

Material	Copper
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Orange
Die Code	50

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	5
Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	12 lbs. per 100

### Application Support


Product Overview	Available on Website
------------------	----------------------

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

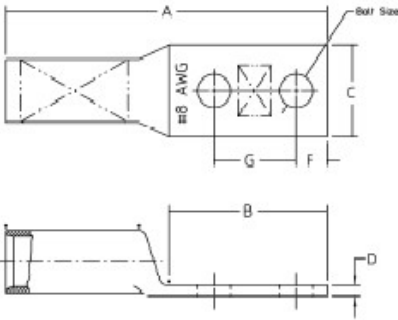

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: techsupport@tnb.com