

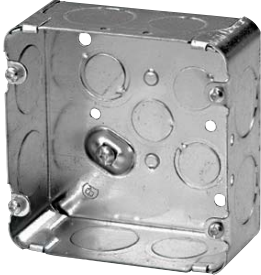

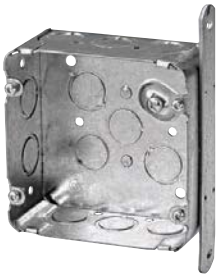
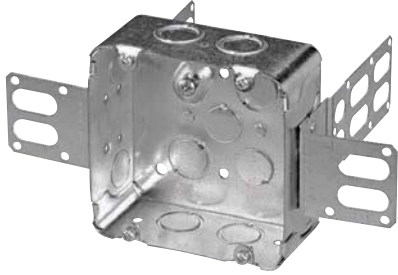
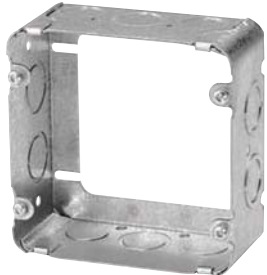


4-11/16 in. Square Boxes

Conduit Knockouts

			
CI72151-K	BC73151-K	CI72171-1	BC72171-K
Concentric knockouts.	Concentric knockouts.	1" knockouts.	Concentric knockouts.
			
CI72171-KSB	CI72171-KSSX	BC73171-K	
Concentric knockouts.	Concentric knockouts / "Wraparound" brackets for 2-1/2 in. and 3-5/8 in. steel studs.	Concentric knockouts.	



Cat. No.	Volume (Cu. in.)	Features		Knockouts				
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom	1 in. sides
1-1/2 in. Deep								
CI72151-K	30.0	-	yes	10	4	6	2	-
BC73151-K	30.0	-	-	10	-	6	-	-
2-1/8 in. Deep								
CI72171-1	42.0	-	yes	-	4	2	2	6
BC72171-K	42.0	-	yes	10	4	6	2	-
CI72171-KSB	42.0	"SB"	yes	8	4	2	2	-
CI72171-KSSX	42.0	"SSX"	yes	4	4	4	2	-
CI72171-1-SSX	42.0	"SSX"	yes	-	4	2	2	4
BC73171-K	42.0	-	-	10	-	6	-	-

4-11/16 in. Square Boxes

Covers



Cat. No.	Description
Flat Covers	
BC72-C-1	Blank
BC72-C-6	With concentric 1/2 in. and 3/4 in. conduit knockout
Single Device Covers	
CI72-C-10	Raised 1/8 in. (1.7 cu. in.)
CI72-C-13	Raised 1/2 in. (4.3 cu. in.)
72 C 14*	Raised 3/4 in. (5.0 cu. in.)
72 C 14 5/8*	Raised 5/8 in. (4.0 cu. in.)
Two Device Covers	
72 C 17*	Raised 1/2 in. (6.3 cu. in.)
72 C 18 5/8*	Raised 5/8 in. (7.5 cu. in.)
Adaptors	
CI72-A-52	To install 4 in. square covers on 4-11/16 in. square boxes. Raised 1/4 in. (3.0 cu. in.)

* UL Listed