

## Cable Ties



**TY523MX**  
Tie body width 0.091 in.



**TY524MX**  
Tie body width 0.140 in.



**TY525MX**  
Tie body width 0.184 in.



**TY5272MX**  
Actual size body width 0.270 in.

The MX Series cable ties are recommended for outdoor use.



Std. Cat. No.	Bulk Cat. No.	Type DSG	Plenum Rating	Usage	ANSI UL94 Flame Rating	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Military Standard Part No.	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Nylon 6/6 – Weather-Resistant												
<a href="#">TY523MX</a>	<a href="#">TY23MX</a>	2/21	AH-2	Indoor/ Outdoor	V-2	0.09/2.29	3.62/91.95	0.87/22.00	MS3367-4	18/80.00	100	1,000
<a href="#">TY52315MX</a>	<a href="#">TYB2315MX</a>						7.00/177.80	1.25/32.00	–			
<a href="#">TY5232MX</a>	<a href="#">TY232MX</a>						8.00/203.20	2.00/51.00	–			
<a href="#">TY5234MX</a>	<a href="#">TY234MX</a>						14.00/355.60	4.00/102.00	–			
<a href="#">TY524MX</a>	<a href="#">TY24MX</a>					0.14/3.56	5.50/139.70	1.38/35.00	MS3367-5	40/180.00		
<a href="#">TY5242MX</a>	<a href="#">TY242MX</a>						8.19/208.03	2.00/51.00	–			
<a href="#">TY526MX</a>	<a href="#">TY26MX</a>						11.10/281.94	3.00/76.00	–			
<a href="#">TY5244MX</a>	<a href="#">TY244MX</a>					14.50/368.30	4.00/102.00	–	30/130.00			
<a href="#">TY525MX</a>	<a href="#">TY25MX</a>					0.19/4.83	7.31/185.67	1.89/48.00	MS3367-1	50/220.00		
<a href="#">TY5253MX</a>	<a href="#">TY253MX</a>						11.60/294.64	3.00/78.00	MS3367-7			
<a href="#">TY528MX</a>	<a href="#">TY28MX</a>	14.20/360.68	4.00/102.00	MS3367-2								
<a href="#">TY5272MX</a>	<a href="#">TY272MX</a>	8.75/222.25	2.00/51.00	–								
<a href="#">TY527MX</a>	<a href="#">TY27MX</a>	2S/21S	N/A	Indoor/ Outdoor	HB	0.27/6.86	13.40/340.36	4.00/102.00	MS3367-3	120/540.00	50	500
<a href="#">TY5275MX</a>	<a href="#">TY275MX</a>						18.00/457.20	5.00/127.00	–			
<a href="#">TY5277MX</a>	<a href="#">TY277MX</a>						24.30/617.22	7.00/177.00	–			
<a href="#">TY529MX</a>	<a href="#">TY29MX*</a>						30.00/762.00	9.00/229.00	MS3367-6			
<a href="#">TY53510MX**</a>	–	N/A	N/A	Indoor/ Outdoor	N/A	0.32/8.13	35.00/889.00	10.00/254.00	–	175/778.40	–	
<a href="#">TY54513MX**</a>	–	N/A					45.00/330.20	13.00/330.20	–			

\* For military compliance of weather-resistant black 120 lb. ties, replace suffix X with O (i.e. TY27M-O).

\*\*

Halogen free, Silicone free

CSA Certified file 002884. Natural 6/6 Nylon Cable Ties are suitable for use in air handling plenum spaces in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC.

Nylon 6/6 is recommended for use in temperatures ranging from -60°C to 85°C (-76°F to 185°F).

## Cable Ties



Std. Pkg. Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Tensile Strength (lb./N)	Std. Pkg.
<b>Ty-Rap® Nylon 6/6 Cable Tie – Colour Assortment</b>					
<b>TY525M-CLRS</b>	0.19/4.83	7.31/185.67	1.75/44.45	50/222.00	100

Cable ties are same size as TY525M shown above. 10 ties in each colour (black, brown, red, orange, yellow, green, blue, purple, grey & white) are packaged. 100 total cable ties per package.



### The colours you need in convenient packs!

#### Ty-Rap® Nylon 6/6 Cable Ties – Colour Assortment

- Construction – nylon 6/6, 316 stainless steel locking device

Std. Cat. No.	Bulk Cat. No.	Description	Type DSG	Plenum Rating	Usage	ANSI UL94 Flame Rating	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Tensile Strength (lb./N)	Std. Pkg.
–	<b>TY525M-CLRS</b>	Multi-Coloured Natural Nylon (10 each of standard ten colours)	2S/21S	AH2	Indoor Only	V2	0.19/4.83	7.31/185.67	1.89/48.00	50/222.00	100
–	<b>TY25M-0</b>	Black, Natural Nylon									1000
–	<b>TY25M-1</b>	Brown, Natural Nylon									
–	<b>TY25M-2</b>	Red, Natural Nylon									
–	<b>TY25M-3</b>	Orange, Natural Nylon									
–	<b>TY25M-4</b>	Yellow, Natural Nylon									
–	<b>TY25M-5</b>	Green, Natural Nylon									
–	<b>TY25M-6</b>	Blue, Natural Nylon									
–	<b>TY25M-7</b>	Purple, Natural Nylon									
–	<b>TY25M-8</b>	Grey, Natural Nylon									
–	<b>TY25M-9</b>	White, Natural Nylon									


For use in temperatures ranging from -60°C to 85°C (-76°F to 185°F)

- UL Listed Natural Nylon 6/6 Cable Ties are suitable for use in air handling spaces (plenums) in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC part I
- CSA Certified file 002884
- 100 standard ties in black, brown, red, orange, yellow, green, blue, purple, grey and white (10 each)
- Recommended tooling – ERG-50, WT1-TB

Natural nylon is standard. For coloured Ty-Rap® ties, add the following suffix numbers to catalogue numbers. **Example:** TY25M-2 would be red TY25M. (Consult Regional Sales Office for ordering information.)

Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.
Black	X	Red	2	Green	5	Grey	8
(outdoor)		Orange	3	Blue	6	White	9
Brown	1	Yellow	4	Purple	7		


**How to Order Coloured Ty-Rap® Cable Ties and Accessories**

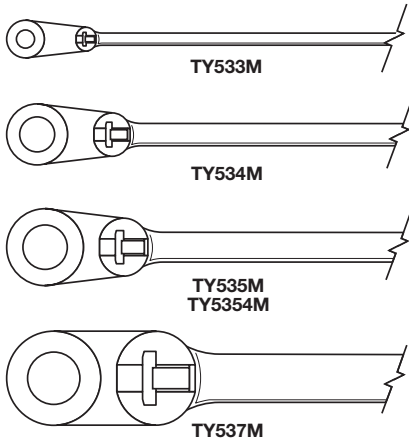

Great for use with screws, nuts and bolts for secure fastening to surfaces.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
<b>Ty-Rap® Mounting Head Cable Ties</b>								
TY533M	TY33M	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000
TY534M	TY34M	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90		
TY535M	TY35M	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40		
TY5354M	TY354M		14.60/370.84	4.00/101.60	#10			
TY1435M	-	0.19/4.83	7.80/198.12	1.77/44.96	0.248		-	
TY635M	-				0.138			
TYF535M	TYF35M		7.24/183.90	0.138	100			
TY537M	TY37M	0.30/7.62	13.90/353.06	3.50/88.90	1/4	120/533.80	50	500

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).

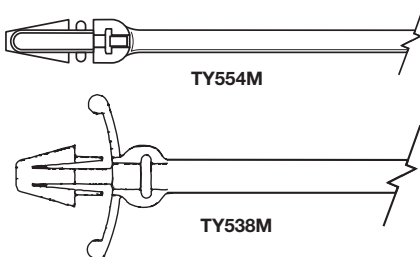


For use in 3/16 in. and 1/4 in. pre-drilled holes. Thickness panel 0.094 max. (TY554M) Range 0.04 - 0.156 (TY538M)

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
<b>Ty-Rap® Push Mount Cable Ties</b>								
TY554M	TY54M	0.14/3.56	5.96/151.38	1.13/28.70	3/16	40/177.90	100	1,000
TY538M	TY38M*	0.18/4.57	7.80/198.12	1.75/44.45	1/4	50/222.40		

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).

\* Nylon 6/6 UV weather-resistant version available (TY38MX).

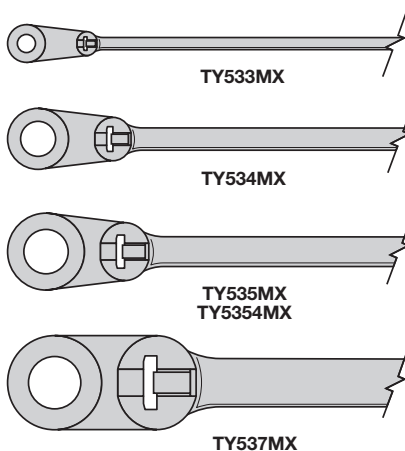

The MX series cable ties are recommended for outdoor use.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
<b>Ty-Rap® Nylon 6/6 Weather-Resistant</b>								
TY533MX	TY33MX	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000
TY534MX	TY34MX	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90		
TY535MX	TY35MX	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40		
TY5354MX	TY354MX		14.60/370.84	4.00/101.60	#10			
TY537MX	TY37MX	0.30/7.62	13.90/353.06	3.50/88.90	1/4	120/533.80	50	500

Colour – Black

For use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).