

# SLMT4-8W

## 4" SLIMLED™ MULTI

### Recess Lighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

### Features

#### Body

Durable airtight plastic body with mounting holes and included butterfly clips. On-face magnets allows for securely attaching one of three included dead front magnetic faceplates (White, Black and Silver).

#### LED Characteristics

This general application light fixture features an 8 watt LED module that maintains uniform intensity producing up to 540 lumens; with a typical CRI of 90. Available in 2700 K, 3000 K, 3500 K or 4000 K colour temperature.

#### Dimming

100%-10% dimming capability. This fixture is compatible with industry standard forward/reverse phase dimmers, TRIAC/ELV dimmers. For compatible dimmers, visit [www.liteline.com/SlimLEDMulti](http://www.liteline.com/SlimLEDMulti)

#### Beam Spread

The fixture lens provides 110° beam spread.

#### Mounting

Can be mounted to a compatible 4" recessed housing via included butterfly clips, or attached to an industry standard 4" octagon box with minimum depth of 1.5" (40mm) via mounting holes.

#### Compatible Recessed Housings

- RF401 series
- RF402 series
- RF405 series

#### LED Driver

Built-in on board driver with 40mA output and 100-135V AC input.

#### Quick Connect push-in terminals

"Quick connect" push-in terminals for fast and easy wiring.

#### Operating Temperature

-30°C~40°C (-22°F~104°F)

#### Environment


- Suitable for wet locations.
- Fire-rated when used in a fire-rated octagon box.

SPECIFICATION	
Application	Recessed / Flushmount Downlight
Approved Location	Wet
Beam Angle	110°
CCT	2700 K / 3000 K / 3500 K / 4000 K
Certification	cETLus
Colour	BK / SL / WH
CRI	90
Dimming	Yes
Dimming Tech	Forward/Reverse phase / TRIAC/ELV
Energy Star	Yes
Hole Cut Size	Ø 4 3/16" (106mm)
Input	100-135V AC, 60Hz
LM79	Yes
LM80	Yes
Lumens	500 / 500 / 520 / 540
Lumens per Watt	62 / 62 / 65 / 67
Power Factor	0.9
Projected Life	70% @ 50,000 hrs
Title 24	Yes (2700 K only)
Warranty	Lifetime
Wattage	8W



### Description

The SLMT4-8W is an 8 watt 4" round downlight for retrofit application onto existing 4" recessed housings or 4" octagon box. It is a high-performance, easy to install residential grade downlight solution that offers good light output, energy-efficiency and streamlined design. Suitable for wet locations.

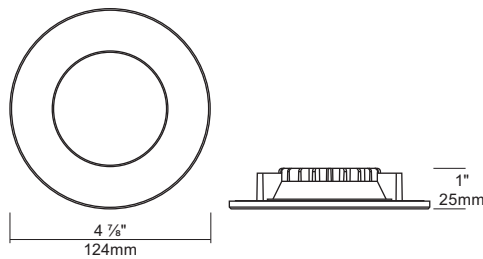

**Notes:** Accessories are sold separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

### Ordering Guide

Colour Temperature
SLMT4-8W <input type="text"/>
27K : 2700 K*
30K : 3000 K
35K : 3500 K
40K : 4000 K

\* Title 24 is currently only available with 2700 K CCT.