


LOW PROFILE, RECESSED **IN BOX** WITH METAL OUTLET BOX

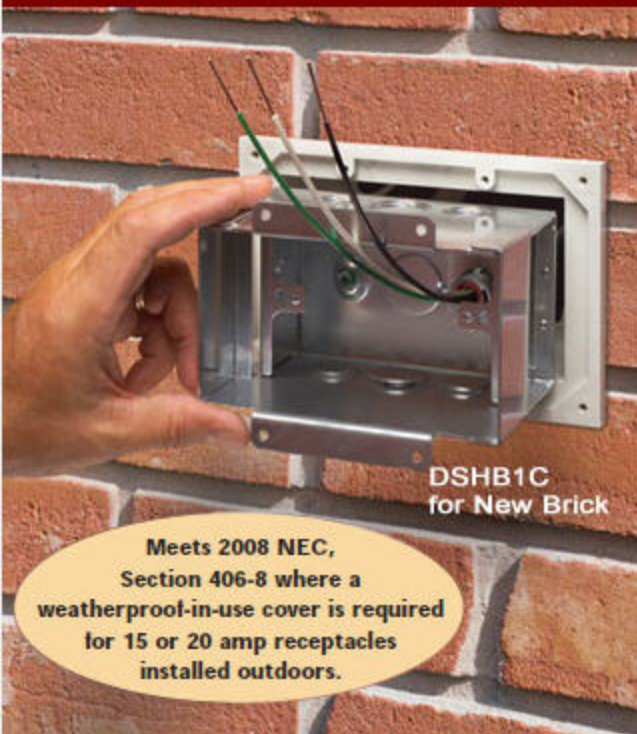

Arlington's new **IN BOX™**, with a metal outlet box, is designed for use in residential and commercial projects with metal raceway systems.



Recessed box

Perfect for installing receptacles outdoors, the job looks great.

IN BOX installs in the wall – so less shows outside!

It's a 25.0 cu. inch metal outlet box with a weatherproof in-use clear or white cover. Plus, we have a style for retrofit; new brick, new vinyl siding and stucco or textured surfaces.

Meets 2008 NEC, Section 406-8 where a weatherproof-in-use cover is required for 15 or 20 amp receptacles installed outdoors.

- No gaskets required – Accepts single-gang devices
- Uses standard and decorative indoor wall plates



Patent Pending.

Colors: Brown box w/ clear cover only • White box w/ clear or white cover

RETROFIT

Vertical Box		Horizontal Box	
Clear Cover	White Cover	Clear Cover	White Cover
DSBVR1C	DSBVR1W	DSBHR1C	DSBHR1W

NEW CONSTRUCTION

	Vertical Box		Horizontal Box	
	Clear Cover	White Cover	Clear Cover	White Cover
New Vinyl Siding	DSBVS1C	DSBVS1W	DSBHS1C	DSBHS1W
Stucco, Textured, Rigid Surface	DSBVM1C	DSBVM1W	DSBHM1C	DSBHM1W

BRICK, NEW CONSTRUCTION, with sleeve adapter

	Clear Cover	White Cover
White Box	DSHB1C	DSHB1W
Brown Box	DSHB1BRC	not offered