

TRAC-MASTER®

Wall Wash/Floods

MINI-BIAX® SERIES
TMBX26

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

Mini-Biax compact fluorescent trac fixtures are an excellent energy efficient solution for residential, retail and commercial wall washing and display illumination. The wide distribution provides uniform illumination and focus on art and feature displays.

PRODUCT SPECIFICATIONS

Lamp One 26W quad compact fluorescent lamp CFQ26/G24d • 2 pin base.

Profile Low profile design.

Aiming 90° vertical aiming capability • 358° horizontal rotation • Two locking knobs provided.

Juno Universal Trac Adapter Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track
 • Copper alloy contacts provide precise spring action – no arcing and will not take a set • True, positive electrical ground • On /off switch included
 • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.

Alternate GTYPE Trac Adapter Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type)
 • System specific and assembled to trac fixture • Consult factory for additional information.

Alternate HTYPE Trac Adapter Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type)
 • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Alternate LTYPE Trac Adapter Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture
 • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Materials Computer contoured reflector • Sturdy extruded aluminum housing with die-cast aluminum end caps and textured paint.

Ballast 120V NPF magnetic ballast

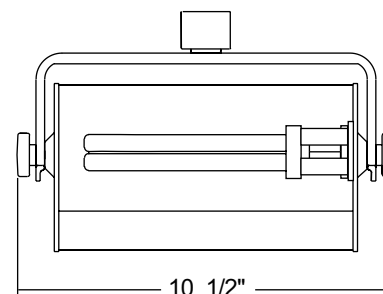
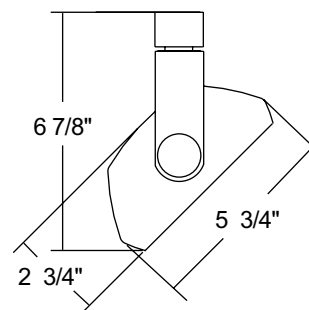
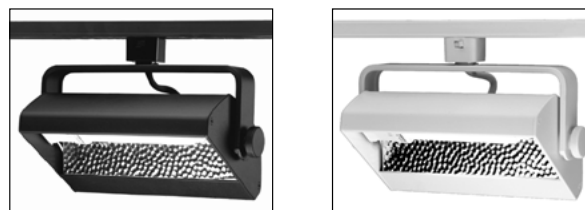
Reflector Hammertone specular aluminum.

Labels UL listed • CSA certified. • Union made • Assembled in U.S.A.

Specifications subject to change without notice.

PRODUCT CODES

Catalog Number	Description	Finish	Wattage and Lamp
TMBX26 WH	Mini-Biax w/Universal Trac Adapter	White	(1) 26W Quad CFL
TMBX26 BL	Mini-Biax w/Universal Trac Adapter	Black	(1) 26W Quad CFL
TMBX26 GTYPE WH	Mini-Biax w/G-Type Trac Adapter	White	(1) 26W Quad CFL
TMBX26 GTYPE BL	Mini-Biax w/G-Type Trac Adapter	Black	(1) 26W Quad CFL
TMBX26 HTYPE WH	Mini-Biax w/H-Type Trac Adapter	White	(1) 26W Quad CFL
TMBX26 HTYPE BL	Mini-Biax w/H-Type Trac Adapter	Black	(1) 26W Quad CFL
TMBX26 LTYPE WH	Mini-Biax w/L-Type Trac Adapter	White	(1) 26W Quad CFL
TMBX26 LTYPE BL	Mini-Biax w/L-Type Trac Adapter	Black	(1) 26W Quad CFL

DIMENSIONS

ENGINEERING DATA

26W, 120V NPF	
Total Input Power	31
Operating Amps	.52
Power Factor	.45
T.H.D.	<20%
Min. Starting Temp.	50°F
Crest Factor	<1.7
Ballast Factor	.87

Biax is a registered trademark of General Electric Corporation.

ConTech is a registered trademark of ConTech Lighting.

1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925 • Visit us at www.acuitybrands.com/juno-trac
 Printed in U.S.A. ©2017-2018 Acuity Brands Lighting, Inc. Rev. 05/16/18

PHOTOMETRIC REPORT

Test Report #: ITL44371

Catalog No: TMBX26

Luminaire: Mini Biax Trac Fixture

Lamp: One 26W Quad CFL lamp rated @ 1850 lumens

TRAC-MASTER®

Wall Wash/Floods

MINI-BIAX® SERIES

TMBX26

FOOTCANDLES ON WALL FROM MULTIPLE UNITS

Fixture Distance to Wall	2'						3'						4'														
	2'	2'	2'	3'	3'	4'	3'	3'	3'	4'	4'	5'	4'	4'	4'	5'	5'	6'									
1'	108	106	108	80	63	80	70	37	70	56	55	56	45	38	45	40	26	40	32	31	32	27	24	27	25	18	25
2'	59	59	59	41	38	41	34	25	34	41	41	41	32	29	32	28	21	28	28	27	28	23	21	23	21	17	21
3'	35	35	35	24	23	24	18	17	18	27	27	27	20	20	20	17	15	17	21	21	21	17	16	17	15	13	15
4'	22	22	22	15	15	15	11	11	11	19	19	19	14	14	14	12	11	12	15	16	15	13	12	13	11	10	11
5'	15	15	15	10	10	10	8	8	8	14	14	14	10	10	10	9	8	9	12	12	12	10	10	10	8	8	8
6'	10	10	10	7	7	7	6	6	6	10	10	10	8	8	8	6	6	6	9	9	9	8	8	8	7	6	7
7'	8	8	8	6	5	6	4	4	4	8	8	8	6	6	6	5	5	5	7	8	7	6	6	6	5	5	5
8'	6	6	6	4	4	4	3	3	3	6	6	6	5	5	5	4	4	4	6	6	6	5	5	5	4	4	4
9'	5	5	5	4	4	4	3	3	3	5	5	5	4	4	4	3	3	3	5	5	5	4	4	4	4	4	4
10'	4	4	4	3	3	3	2	2	2	4	4	4	3	3	3	3	3	3	4	4	4	4	4	4	3	3	3

