

JUNO®

TRAC-MASTER®

Low Voltage

SPOTLIGHTS

T442, T443 and TP443

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

Low voltage fixtures offer precise control and energy efficiency for accent lighting and display applications.

Transformer Must be ordered separately • Compatible with T537 or T538 12V electronic transformer for halogen lamps (D1.2.1) • Compatible with T537 LED universal 12V electronic transformer for LED or halogen lamps (D1.2.5)
 • Compatible with T539 12V electronic transformer for halogen lamps (D1.2.0)
 • Compatible with T543 12V magnetic transformer for LED or halogen lamps (D1.2.0).

Aiming 90° vertical aiming capability and 358° rotation.

Labels UL listed, CSA certified.

Specifications subject to change without notice.



Low Voltage MR16

Construction Die-cast aluminum housing with steel yoke.

Lamp 12V, 50W maximum MR16 GU5.3/GX5.3 bi-pin.

Socket Ceramic bi-pin.


Catalog Number	Description	Finish	Lamp
T443 WH	Notch Back	White	50W MR16 max.
T443 BL	Notch Back	Black	50W MR16 max.

ACCESSORIES

Cat. No.	Description	Cat. No.	Description
CGF 175	Color Glass Filter	DIFF 175	Diffuse Glass Lens
DCCF 175	Dichroic Color Corection Filter	LSPREAD 175	Linear Spread Glass Lens
DGF 175	Dichroic Glass Filter	SOLITE 175	Uniformity Lens (Solite)
UVF 175	UV Filter	HCLBL 175	Hexagonal Cell Louver - Black

PRISM 175 Prismatic Spread Glass Lens

See specification sheet [D1.2.2](#) for details.

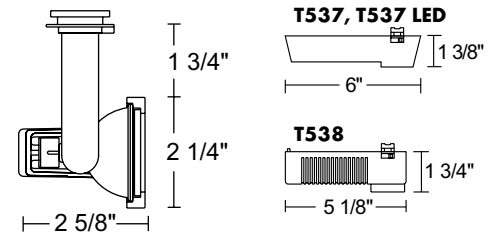

Low Voltage MR16

Construction Die-cast aluminum housing with steel clip and rod.

Lamp 12V, 50W maximum MR16 GU5.3/GX5.3 bi-pin.

Socket Ceramic bi-pin.


Catalog Number	Description	Finish	Lamp
TP443 WH	Pendant Notch Back	White	50W MR16 max.
TP443 BL	Pendant Notch Back	Black	50W MR16 max.

ACCESSORIES

Cat. No.	Description	Cat. No.	Description
CGF 175	Color Glass Filter	DIFF 175	Diffuse Glass Lens
DCCF 175	Dichroic Color Corection Filter	LSPREAD 175	Linear Spread Glass Lens
DGF 175	Dichroic Glass Filter	SOLITE 175	Uniformity Lens (Solite)
UVF 175	UV Filter	HCLBL 175	Hexagonal Cell Louver - Black

PRISM 175 Prismatic Spread Glass Lens

See specification sheet [D1.2.2](#) for details.

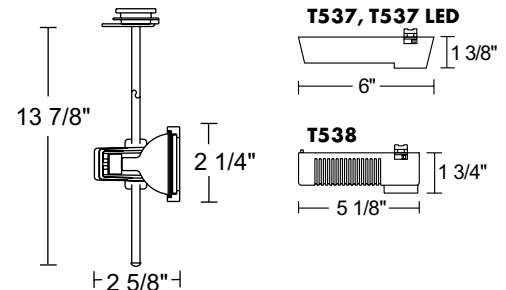

TRAC-MASTER®

Low Voltage

SPOTLIGHTS**T442, T443 and TP443****Low Voltage MR16****Construction** Steel housing and yoke, die-cast aluminum bezel.**Lamp** 12V, 50W maximum MR16 GU5.3/GX5.3 bi-pin.**Socket** Ceramic bi-pin with integral heat shield.

Catalog Number	Description	Finish	Lamp
T442 WH	Round Back Cylinder	White	50W MR16 max.
T442 BL	Round Back Cylinder	Black	50W MR16 max.

ACCESSORIES

Cat. No.	Description	Cat. No.	Description
CGF 175	Color Glass Filter	DIFF 175	Diffuse Glass Lens
DCCF 175	Dichroic Color Corection Filter	LSPREAD 175	Linear Spread Glass Lens
DGF 175	Dichroic Glass Filter	SOLITE 175	Uniformity Lens (Solite)
UVF 175	UV Filter	HCLBL 175	Hexagonal Cell Louver - Black
PRISM 175	Prismatic Spread Glass Lens	SNOOTBL 175	Snoot Accessory - Black

See specification sheet [D1.2.2](#) for details.