

Classics

**T308, T620, T63,  
T64, T691 and T359**

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

### PRODUCT DESCRIPTION

Universals offer a wide range of lamp options depending on the application.

**Socket** Medium base porcelain with nickel plated copper screw shell • Socket adjustable for proper lamp positioning (except T359).

**Juno Universal Trac Adapter** Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track • Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.

**Alternate GTYPE Trac Adapter** Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type) • System specific and assembled to trac fixture • Consult factory for additional information.

**Alternate HTYPE Trac Adapter** Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type) • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

**Alternate LTYPE Trac Adapter** Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

**Labels** UL listed, CSA certified.

Specifications subject to change without notice.



### Line Voltage Universal



**Construction** Drawn steel housing with steel yoke.

**Aiming** 90° vertical aiming capability and 358° rotation • One locking knob provided.

Catalog Number	Description	Finish	Lamp
<b>T308 WH</b>	Universal w/Universal Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
<b>T308 BL</b>	Universal w/Universal Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38

#### ACCESSORIES

Catalog Number	Finish	Description	Max. Lamp
<b>T63 WHT</b>	White w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
<b>T63 BLCK</b>	Black w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
<b>T64 WHT</b>	White w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40
<b>T64 BLCK</b>	Black w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40

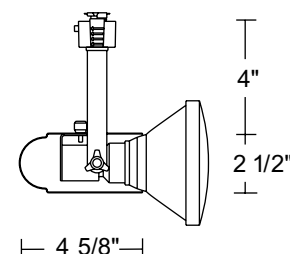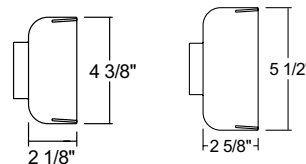

### Economy Line Voltage Universal



**Construction** Steel housing with steel yoke.

**Aiming** 90° vertical aiming capability and 358° rotation.

Catalog Number	Description	Finish	Lamp
<b>T620 WH</b>	Universal w/Universal Trac Adapter	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38
<b>T620 BL</b>	Universal w/Universal Trac Adapter	Black	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/150W PAR38

#### ACCESSORIES

Catalog Number	Finish	Description	Max. Lamp
<b>T63 WHT</b>	White w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
<b>T63 BLCK</b>	Black w/ Black Baffle	Baffled Hood	75W PAR30L/65W BR30
<b>T64 WHT</b>	White w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40
<b>T64 BLCK</b>	Black w/ Black Baffle	Baffled Hood	150W PAR38/120W BR40

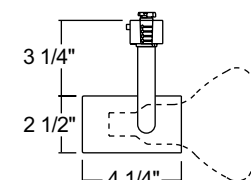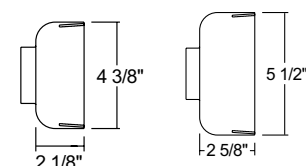

ConTech is a registered trademark of ConTech Lighting.


One Lithonia Way • Conyers, GA 30012 • Phone 1-800-705-SERV (7378) • Visit us at [www.acuitybrands.com](http://www.acuitybrands.com)  
Printed in U.S.A. ©2017-2020 Acuity Brands Lighting, Inc. Rev. 03/11/20

**TRAC-MASTER®**

Classics

**UNIVERSALS****T308, T620, T63,  
T64, T691 and T359****Hi-Tech Mini Swivel Universal****Construction** Steel housing with slotted steel swivel.**Aiming** 90° vertical aiming capability and 358° rotation • One locking knob provided.

Catalog Number	Description	Finish	Lamp
<b>T691 WH</b>	Universal w/Universal Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 BL</b>	Universal w/Universal Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 NA</b>	Universal w/Universal Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 GTYPE WH</b>	Universal w/G-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 GTYPE BL</b>	Universal w/G-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 GTYPE NA</b>	Universal w/G-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 HTYPE WH</b>	Universal w/H-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 HTYPE BL</b>	Universal w/H-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 HTYPE NA</b>	Universal w/H-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 LTYPE WH</b>	Universal w/L-Type Trac Adapter	White	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 LTYPE BL</b>	Universal w/L-Type Trac Adapter	Black	60W PAR16/50W PAR20/75W PAR30/150W PAR38
<b>T691 LTYPE NA</b>	Universal w/L-Type Trac Adapter	Natural	60W PAR16/50W PAR20/75W PAR30/150W PAR38

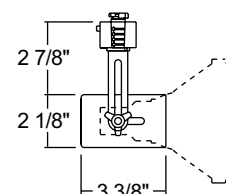**Mini Swivel Universal****Construction** Porcelain socket mounted to low profile steel swivel.**Aiming** 90° vertical aiming capability and 358° rotation.

Catalog Number	Finish	Lamp
<b>T359 WH</b>	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
<b>T359 GTYPE WH</b>	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
<b>T359 HTYPE WH</b>	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38
<b>T359 LTYPE WH</b>	White	50W R20/50W PAR20/85W BR30/75W PAR30/120W BR40/250W PAR38

