



TRAC-MASTER®

Avant Garde

DELTA 200 SERIES

T218

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

The Delta 200 Series attains the ultimate caliber of clean lines in today's popular open fixture look. The die cast aluminum exterior features the detailed styling of a precision lighting instrument with a sleek vented look.

Construction Die cast aluminum body.

Socket Medium base porcelain with nickel plated copper screw shell.

Aiming 90° vertical aiming capability and 358° rotation • One locking screw provided.

Juno Universal Trac Adapter Universally compatible with both Trac-Master 1-circuit or 2-circuit trac, Trac-Lites trac, monopoints and special mountings • Also UL Recognized for use on ConTech® LT Series track • Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • Two-position power contact provided for two-circuit application.

Alternate GTYPE Trac Adapter Compatible with track systems based on GES type track, including Lithonia LT Commercial Track (not LTS type)

• System specific and assembled to trac fixture • Consult factory for additional information.

Alternate HTYPE Trac Adapter Compatible with track systems which use a H-type track adapter, including Lithonia LTS Decorative Track (not LT type) • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.

Alternate LTYPE Trac Adapter Compatible with track systems which use a L-type track adapter • System specific and assembled to trac fixture • Two-position power contact provided for two-circuit application • Consult factory for additional information.


Labels UL listed • CSA certified • Union made • Assembled in U.S.A.

Specifications subject to change without notice.



Line Voltage PAR30

Catalog Number	Description	Finish	Lamp
T218 WH	Delta 200 w/Universal Trac Adapter	White	75W PAR30 max.
T218 BL	Delta 200 w/Universal Trac Adapter	Black	75W PAR30 max.
T218 SL	Delta 200 w/Universal Trac Adapter	Silver	75W PAR30 max.
T218 GTYPE WH	Delta 200 w/G-Type Trac Adapter	White	75W PAR30 max.
T218 GTYPE BL	Delta 200 w/G-Type Trac Adapter	Black	75W PAR30 max.
T218 GTYPE SL	Delta 200 w/G-Type Trac Adapter	Silver	75W PAR30 max.
T218 HTYPE WH	Delta 200 w/H-Type Trac Adapter	White	75W PAR30 max.
T218 HTYPE BL	Delta 200 w/H-Type Trac Adapter	Black	75W PAR30 max.
T218 HTYPE SL	Delta 200 w/H-Type Trac Adapter	Silver	75W PAR30 max.
T218 LTYPE WH	Delta 200 w/L-Type Trac Adapter	White	75W PAR30 max.
T218 LTYPE BL	Delta 200 w/L-Type Trac Adapter	Black	75W PAR30 max.
T218 LTYPE SL	Delta 200 w/L-Type Trac Adapter	Silver	75W PAR30 max.

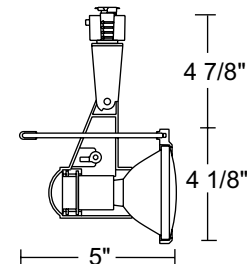

ACCESSORIES

Cat. No.	Description	Cat. No.	Description	Cat. No.	Description
HCLBL 375	Hexcell Louver - Black	DGF 375	Dichroic Glass Filter	PRISM 375	Prismatic Spread Glass Lens
CCLBL 375	Cube Cell Louver - Black	DCCF 375	Dichroic Color Correction Filter	LSPREAD 375	Linear Spread Glass Lens
SNOOTBL 375	Snoot - Black	UVF 375	UV Filter	T660BL	3-3/4" Diameter Accessory Holder - Black †
EYEBROWBL 375	Eyebrow Accessory - Black	DIFF 375	Diffusion Glass Lens	T40N¹	Monopoint
CGF 375	Color Glass Filter	SOLITE 375	Uniformity Lens (Solite)		

See specification sheet [D1.2.2](#) for details. Other accessories can be found on specification sheet [D1.2.0](#).

† Filters and lenses require accessory holder for installation.

Notes:

¹ Add finish code to complete catalog number (Example: T40N WH).

ConTech is a registered trademark of ConTech Lighting.