






COMMUNICATION MODULE COM060 ACCESSORY FOR: 3VA6
150/250



Model	
Product brand name	SENTRON
Product designation	COM060 communication module
Design of the product	Accessories for 3VA
accessories	Communication and measurement function
General technical data	
Suitability for operation	3VA6 150/250 and COM800
Mounting position	Right switch pocket
Degree of pollution	3
Overvoltage category	1
Safety class	III according to IEC61558
Protection class IP	20 acc. to IEC60529
Mechanical Design	
Number of interfaces / of the circuit breaker communication system	1
Length / of the supplied connecting cable / for circuit breaker communication system	0.15 m
Type of electrical connection / of the circuit breaker communication interface	Spur line via T feeder

Total length / of the circuit breaker communication system	20 m
Power loss [W] / rated value	2.4 W
Consumed current / maximum	0.1 A
Height	63 mm
Width	29 mm
Number of slots	4
Depth	33 mm
Net weight	90 g

Certificates

General Product Approval	EMC	Declaration of Conformity	other
 CSA	 UL	 EAC	 RCM
		 EG-Konf.	Miscellaneous

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9177-0TB10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9177-0TB10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9177-0TB10

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

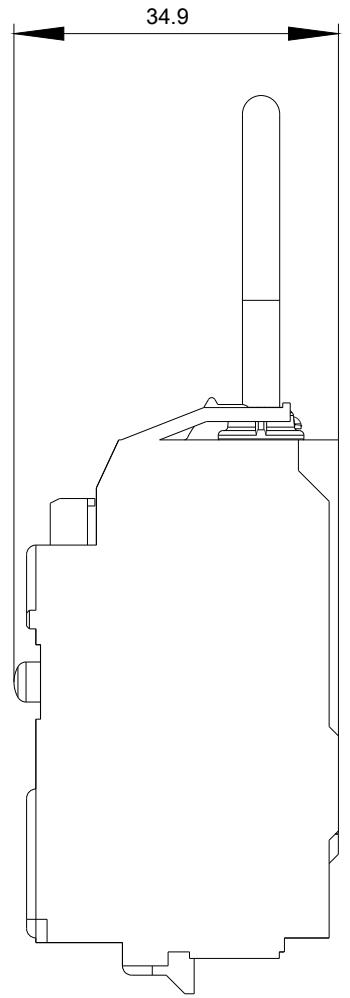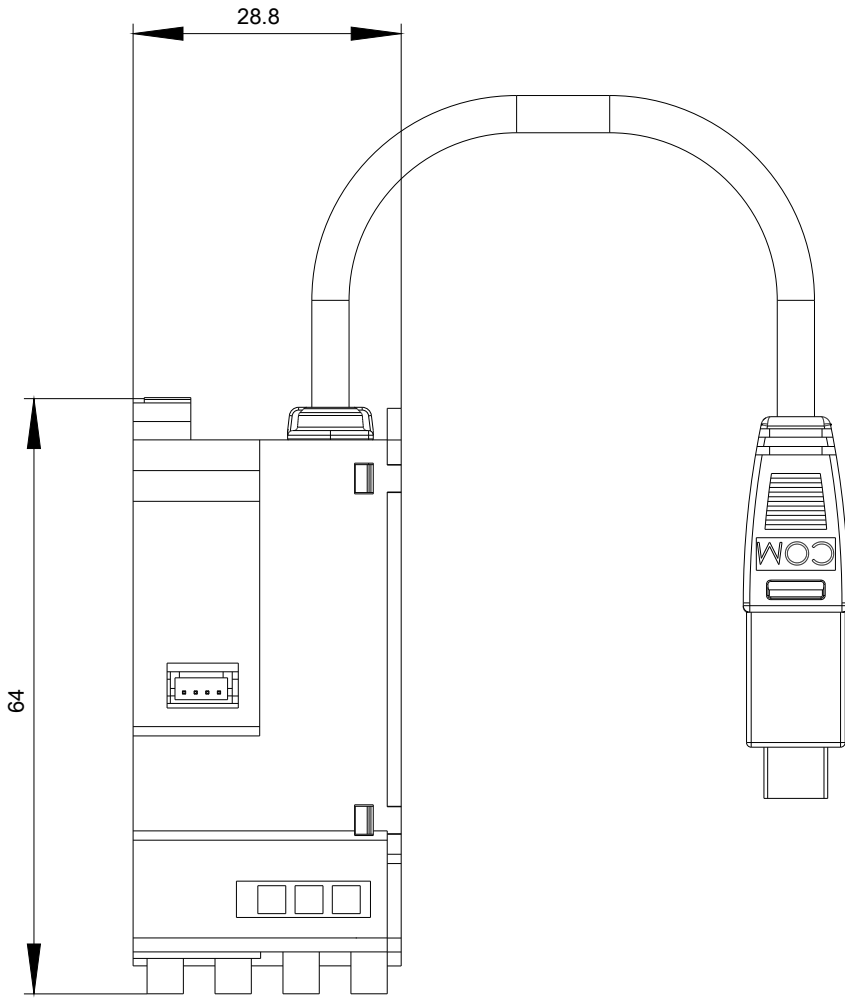

last modified:

11/17/2017