

FEATURES & SPECIFICATIONS

INTENDED USE — Recessed housing rated IC and Airtight as standard.

Meets Washington State Energy Code.

Approved for all ceiling and wiring types.

New construction only.

Approved for direct burial in insulation.

CONSTRUCTION — Steel inner housing.

Aluminum outer housing.

Galvanized bar hangers span up to 24" O.C. and feature built-in nailer and T-bar clips.

Galvanized steel junction box with 4 built-in Romex clamps; (2) 1/2" and 3/4" knockouts with slots for pryout. Rated for through branch wiring.

Maximum 4 (2 in, 2 out) No.12 AWG conductors, rated for 90°C.

Ground wire provided.

Removable J-box doors for easy access.

ELECTRICAL — Two-pin porcelain socket with heat shield.

Thermal protection provided against improper lamp usage.

Precision-wound stepdown transformer with class H insulation. For dimming control, use only dimmers specifically designed for use with electromagnetic transformers 120V only, 50W MR16 maximum.

INSTALLATION — 2 x 8 wood joist or T-bar installation.

Expandable bar hangers allow for off center mounting in wood joist or T-bar ceilings. Length of 25-1/4" maximum 13-1/4" minimum or cut to fit 7-1/2" on center joist construction.

Ceiling cutout 4-3/16"

LISTINGS — UL Listed to U.S. and Canadian safety standards.

Damp location listing.

WARRANTY — 1-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Specifications subject to change without notice.


Catalog Number
Notes
Type

4" Housing

LIV3

LOW VOLTAGE

IC
New Construction

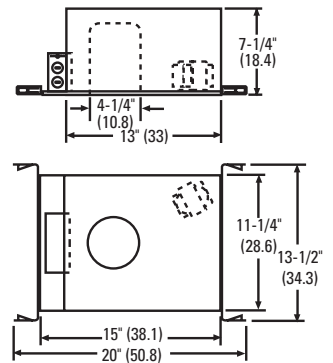

Specifications

Height: 7-1/4 (18.4)

Length: 20 (50.8)

Width: 13-1/2 (34.3)

All dimensions are inches (centimeters) unless otherwise indicated.

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: LIV3

LIV3
Series
LIV3

LIV3 4" Low Voltage Housing

Description Catalog number	Maximum wattage	Description Catalog number	Maximum wattage
-------------------------------	-----------------	-------------------------------	-----------------

General/Task

Open, Adjustable

3V01AZ	Clear specular
3V01GZ	Gold specular
3V01BLZ	Black specular



50 MR16

IC

Baffle, Adjustable

3VB1	Black
3VB1W	White



50 MR16

IC

Baffle Slotted Adjustable
3VA5 White



50 MR16

IC

Pinhole Wide Flange
3VS1 White




50 MR16

IC

Accent/Wallwash

Eyeball

3VE1	White
-------------	-------

 

50 MR16

IC

Baffle Eyeball

3VE2	Black
3VE2W	White



50 MR16

IC

Eyelid Wallwasher

3VW1	White
-------------	-------



50 MR16

IC

Directional Wallwash

3VDW1W	White
---------------	-------



50 MR16

IC