


YP26AU2

by Burndy
Catalog ID: YP26AU2

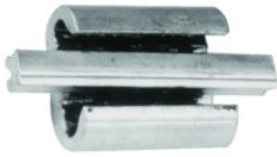

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 1, 1/0, 2/0, 3/0.

Features: Wide Range, Universal And Reversible, Figure 3 -Shaped Aluminum Connector With Adjustable Overhanging Spacer That Separates Conductors, Spacer Holds Run Or Tap In Place Permitting Lineman To Either Approach The Line Ready To Crimp, Or To Assemble Connector And Tap On Run And Then Crimp, Massive Aluminum Design Minimizes Conductor Corrosion Due To Galvanic Action, Pre-Filled With PENETROX Joint Compound And Stripsealed, Conductor Range And Tooling Information Clearly Printed On Connector And Package, Tools, Die Set Catalog Number, And (number Of Crimps): MD6, MD7 Tool, W-O Die, (4), Y35, Y750 Tool, U-O Die, (1), Y45 Tool, U-O Die With PT-6515 Adapter, (1), Y46 Tool, U-O Die With PUADP-1 Adapter, (1), Die Index: O Element A, Conductor Type: Run: ACSR, ACSR Compressed, Stranded Aluminum, Solid Aluminum, Solid Copper, Stranded Aluminum Compressed, Stranded Copper, Tap: ACSR, ACSR Compressed, Stranded Aluminum, Solid Aluminum, Solid Copper, Stranded Aluminum Compressed, Stranded Copper, Conductor Size (tap Range): 6 - 1/0 AWG, Conductor Size (run - Range): 6 - 3/0 AWG, Shape: 3

Product Details

General

Application	For Copper, Aluminum Or ACSR Conductors
Die Index	O
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	CABELOK CRIMPIT
Trade Name	CABELOK™ CRIMPIT™
Type	YP-U
UPC	781810130650
UPC 12 Digit	7818101306500

Dimensions

Dimension - Height inch	1.30 in
Dimension - Length Overall inch	1.50 in
Dimension - Width inch	0.72 in

Conductor Related

Conductor - ACSR Str Size A	3 (6/1) Swallow AWG; 2 (6/1) Sparrow AWG; 2 (7/1) Sparate AWG; 1 (6/1) Robin AWG; 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size A Range	3 (6/1) Swallow AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B	6 (6/1) Turkey AWG; 5 (6/1) Thrush AWG; 4 (6/1) Swan AWG; 4 (7/1) Swanate AWG; 3 (6/1) Swallow AWG; 2 (6/1) Sparrow AWG
Conductor - ACSR Str Size B Range	6 (6/1) Turkey AWG-2 (6/1) Sparrow AWG

Conductor - AL Str Size A	3 AWG;2 AWG;1 AWG;1/0 AWG
Conductor - AL Str Size A Range	3 AWG-1/0 AWG
Conductor - AL Str Size B	6 AWG;4 AWG;3 AWG;2 AWG
Conductor - AL Str Size B Range	6 AWG-2 AWG
Conductor - Copper Solid Size A	1 AWG;1/0 AWG;2/0 AWG;3/0 AWG
Conductor - Copper Solid Size A Range	1 AWG-3/0 AWG
Conductor - Copper Solid Size B	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG
Conductor - Copper Solid Size B Range	1 AWG-3/0 AWG
Conductor - Copper Str Size A	2 AWG;1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Size A Range	2 AWG-2/0 AWG
Conductor - Copper Str Size B	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG
Conductor - Copper Str Size B Range	6 AWG-1 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Minimum Pack Quantity	1
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)