


PRODUCT-DETAILS

# H600-TB

## 6 INCH CONDUIT FITTING

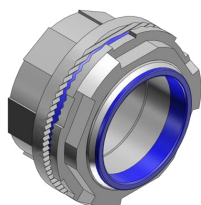

### General Information

Extended Product Type	H600-TB
Product ID	7TBD013790R0023
EAN	0786210898667
Catalog Description	6 INCH CONDUIT FITTING
Long Description	6 Inch Zinc Hub Connector with Thermoplastic Insulating Throat, Sealing Ring Nitrile (BUNA-N) for Use with Rigid/IMC Conduit

### Ordering

EAN	0786210898667
Customs Tariff Number	8547900030

### Dimensions

Product Net Weight	7.2 lb 3.265 kg
--------------------	--------------------

### Container Information

Package Level 2 Units	1 piece
Package Level 2 Width	4.1 in 104 mm
Package Level 2 Height	8.8 in

	224 mm
Package Level 2 Depth / Length	9.1 in 231 mm

**Additional Information**

Application	To Connect Threaded Metal Conduit to a Threadless Opening in a Box or Enclosure
Brand / Label	T&B
Material	Zinc
Number of Batteries	0
Product Name	INSULATED CONDUIT FITTING
Product Type	Hub Connector
Size	6 Inch
Special Functions	Sealing Ring and Groove with Innovative Profile Better Than Standard O-Ring
Standards	UL E23018, CSA
Temperature Range	105 °C
UPC	786210898667

**Certificates and Declarations (Document Number)**

Data Sheet, Technical Information	H600-TB
Instructions and Manuals	H600-TB

**Classifications**

ETIM 6	EC001180 - Screw connection for protective metallic hose
ETIM 7	EC001180 - Screw connection for protective metallic hose
UNSPSC	39121311
WEEE Category	Product Not in WEEE Scope
IDEA Granular Category Code (IGCC)	4441 >> Electrical fittings

**Categories**

Low Voltage Products and Systems → Installation Products → Cable Protection, Explosion Proof and Lighting → Rigid Cable Protection Systems

