

All-In-One Electrical Assemblies

ALL-IN-ONE FLOOR-MOUNTED ASSEMBLIES

ALL-IN-ONE FLOOR-MOUNTED WITH REMOVABLE MUD RING

- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Removable mud ring provides front access to the interior of the box
- Box remains fixed in place when mud ring is removed
- Integrated first means of support accepts conduit or MC/AC cable
- Accommodates additional All-In-One box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Made in the USA



Patent Pending

Material: Steel

Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) 1/2"; 3/4", (3) 1/2"



| Part Number | Description |  |
|-------------|------------------------------------------|-------------------------------------------------------------------------------------|
| A1FF1GS | 1 Gang, w/Ground, 5/8" Drywall, 2 1/2" | 5 pc |
| A1FF1G | 1 Gang, w/Ground, 5/8" Drywall, 3 5/8" | 5 pc |
| A1FF3G | 1 Gang, w/Ground, 1 1/4" Drywall, 3 5/8" | 5 pc |
| A1FF2GS | 2 Gang, w/Ground, 5/8" Drywall, 2 1/2" | 5 pc |
| A1FF2G | 2 Gang, w/Ground, 5/8" Drywall, 3 5/8" | 5 pc |
| A1FF4G | 2 Gang, w/Ground, 1 1/4" Drywall, 3 5/8" | 5 pc |

Ground wire pigtail is 8".

All-In-One Electrical Assemblies

ALL-IN-ONE FLOOR-MOUNTED ASSEMBLIES

ALL-IN-ONE FLOOR-MOUNTED WITHOUT MUD RING

- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Integrated first means of support accepts conduit or MC/AC cable
- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Accommodates additional All-In-One box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Works with standard US and Canadian mud rings
- Made in the USA



Patents Pending

Material: Steel


Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) 1/2"; 3/4", (3) 1/2"



| Part Number | Description |  |
|-------------------|------------------|-------------------------------------------------------------------------------------|
| A1FF0G | w/Ground, 3 5/8" | 5 pc |
| A1FF0GTC (Canada) | w/Ground, 3 5/8" | 5 pc |
| A1FF0GS | w/Ground, 2 1/2" | 5 pc |


Ground wire pigtail is 8".

All-In-One Electrical Assemblies

ALL-IN-ONE FLOOR-MOUNTED ASSEMBLIES

ALL-IN-ONE FLOOR-MOUNTED BRACKET

- Versatile bracket for mounting All-In-One box assemblies
- Positions box a fixed distance from the floor eliminating the need to measure and promoting consistent placement
- Provides excellent rigidity and reduces issues at trim out
- Dual mounting tabs allow bracket to be installed on either side of the stud
- Integrated first means of support accepts conduit or MC/AC cable
- Accommodates additional All-In-One box assemblies, support brackets and low-voltage mounting plates
- Made in the USA

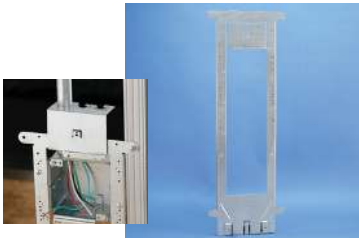

Material: Steel

Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3



| Part Number | Description |  |
|-------------|----------------------------------|------------------------------------------------------------------------------------|
| A1F1218 | All-In-One Floor-Mounted Bracket | 15 pc |