

Smooth baffle, round

When choosing a recessed fixture, eliminating glare is a priority. The unique positioning of the LED module in this series of downlights will meet that important need.



Model	Size	Watts	Delivered lumens	LED lumens	CRI	Color °T	Voltage
RGR2-3K	2"	8 W	600 lm	750 lm	90	3000 K	120 V
RGR4-3K	4"	14 W	990 lm	1200 lm	90	3000 K	120 V
RGR6-3K	6"	20 W	1600 lm	1900 lm	90	3000 K	120 V

Specifications

Every fixture includes a junction box with integrated dimmable driver
 Can be daisy chained
 Superior LED performance and lifespan
 Regressed light source
 Minimal heat emission
 Aluminum construction
 IC certification (suitable for direct contact with insulation)
 Air-tight certified as per ASTM E283-04
 Suitable for wet locations

Finish


BK Black
SN Satin Nickel
WH White

Accessories

RFP-UNI
 Universal rough-in plate


Order example

RGR4-3K-BK
 Dimmable RGR4-3K 4" round regressed LED fixture in a black finish

RGR2-3K Ø2 3/4" 



Ø3 1/8" x 2 3/4"

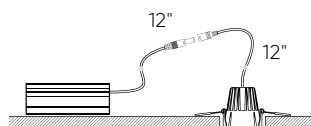


4 13/16" x 2" x 2"

RGR4-3K Ø4" 



Ø4 1/2" x 2 3/4"

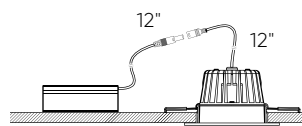


5 3/8" x 3" x 1 1/4"

RGR6-3K Ø6 1/2" 



Ø7" x 3"

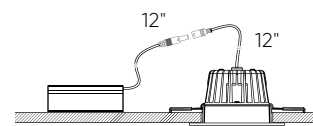

5" x 3 5/16" x 1 1/4"