



APPLICATION

For most commercial medium- to large-area outdoor applications requiring high-efficiency lighting. Fixture is designed with no cut-off feature, allowing the fixture to cast illumination into 180 degree direction. Prismatic clear glass refractor is designed to symmetrically spread a uniform lighting distribution. Not appropriate for direct high pressure water applications.

CONSTRUCTION

Die-cast aluminum housing with hinged door frame. The one-piece silicone gasket effectively limits outside contaminants by sealing off the optical chamber. The reflector is made of die-formed specular anodized aluminum for high efficiency.

FINISH - Dark bronze corrosion- and UV-resistant polyester powder finish is standard.

OPTICS - High-performance LEDs maintain at least 70% of light output at 50,000 hours of service life.

LENS - Prismatic glass refractor made of borosilicate material.


INSTALLATION - Convenient, easy mount over standard 4" outlet box or use 1/2" surface conduit. Top, side and back conduit entry taps.

LISTINGS - UL/C-UL for wet location.

WARRANTY - Limited 5 Year Warranty.

All specifications are subject to change without notice

Dimensions:

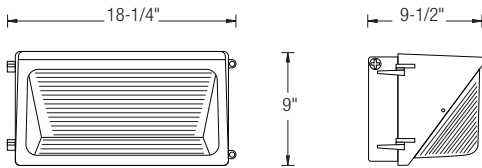

LED
OWP

LED Large No Cut-Off Wall Pack

Ordering Information: Example: OWP-NC-301-LED-6000L-MVOLT

OWP-NC-301-LED

SERIES

OWP-NC-301-LED-
Oracle LED No Cut-Off
Wall Pack

LUMENS

6000L - (6000 lumens)

VOLTAGE

MVOLT

CCT

41K - (4100K)

* For more CCT
option, consult
factory

FINISH

BZ - Bronze

For more finish
option, consult
factory

OPTION

PHC - Photo cell