



### DESCRIPTION

Slim to size and bright in lumen output.  
 With a width of 1/4", the puck light can be recess or surface mounted.  
 Easily swap the trim color with the magnetic technology engineered into the pucks.  
 Connect the puck lights to the power supply using a 6-port hub and wires already integrated.  
 Puck lights can be purchased in single packs or in three packs that include a transformer.

### FEATURES & BENEFITS



Fast & Easy to install - save on labor  
 CRI 90+ for true color rendering

### DIMENSIONS ID 2 1/4" OD 3"



### Your Choice Of Installation

1/4" Thin Surface Mounted      1/8" Thin Recessed Mounted

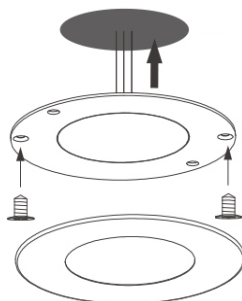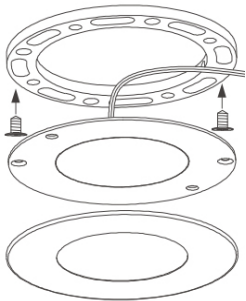

### ORDERING GUIDE

Single 3000K	<b>AD-107T-3K</b>
Single 4000K	<b>AD-107T-4K</b>
3 Pack 3000K	<b>3P-AD-107T-3K</b>
3 Pack 4000K	<b>3P-AD-107T-4K</b>

Project: \_\_\_\_\_

Location: \_\_\_\_\_


Qty: \_\_\_\_\_

Notes: \_\_\_\_\_

### SPECIFICATION

Applications	Undercabinet, Cove, Hospitality, Retail Lighting
Energy Used	2.2 W
Color Temperature (K)	3000   4000
Light Output (lm)	150   170
Halogen Equivalent	15 W
Beam Angle	120°
CRI	90 +
Input	12V DC
Dimming	Plug-in Driver not Dimmable
	Hard Wired Driver TRIAC Dimmable 10% - 100%
Air Tight	Yes
Ambient Temperature	-4° F (-20° C) to +104° F (+40° C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus
Warranty	3 Year

### Trims and Surface Mounting Bracket Included

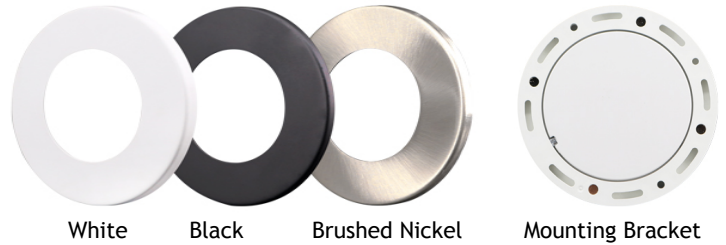

White      Black      Brushed Nickel      Mounting Bracket

### 3 Pack Option



Included: 3 Pucks with WH, BK & BN Trims, Cables and 6 Port Hub  
 Plug-in Driver 120VAC 12W Non Dimmable

### ACCESSORIES

Sold Separately



Hard Wired Triac Dimmable Driver 24W cat # HBL024-120-12-D



6-Port Hub cat # AD-107THB1