

Tmax T ranges

T7-T7M Accessories

4




Motor operators

Spring charging motor operators

Control voltage type	T7M
	Part number
24...30V ac/dc	KT7MXM9
48...60V ac/dc	KT7MXM7
110...130V ac/dc	KT7MXM5
220...250V ac/dc	KT7MXM3
380...415Vac	KT7MXM2

Electrical signals

Standard auxiliary contacts (AUX)

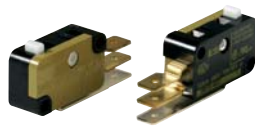

Auxiliary contact type	T7	T7M
	Part number	Part number
1 form C + 1 BA 400Vac	KT7AS	-
1 form C + 1 BA 24Vdc	KT7ASL	-
2 form C 400Vac	KT7XAS2	KT7XAS2
2 form C 24Vdc	KT7XAS2L	KT7XAS2L
S51 Alarm contact 250Vac	KT7S51	KT7XS51
Ready-to-Close contact 250V ac/dc	-	KT7XRTC250
Ready-to-Close contact 24Vdc	-	KT7XRTC24
Spring charged contact 250V ac/dc	-	KT7XSC250
Spring charged contact 24Vdc	-	KT7XSC24
1BA + remote reset 24...30V ac/dc	-	KT7XETBAR9
1BA + remote reset 110...130V ac/dc	-	KT7XETBAR5
1BA + remote reset 200...240V ac/dc	-	KT7XETBAR4
Position contact set withdrawable 250Vac	KT7XAUP250	KT7XAUP250
Position contact set withdrawable 24Vdc	KT7XAUP24	KT7XAUP24

Possible combinations with auxiliary contacts on T7-T7M (excluding S51, RTC, SC and AUP contacts)

Combination type	T7	T7M
	Part number	Part number
2 form C	YES	YES
4 form C	NO	YES
2 form C + 1 BA	YES	NO
3 form C + 1 BA	YES	NO

Early make contact for rotary handle



Contact type	T7
	Part number
Early make contact	KT7EM