

120VOLT ARCHITECTURAL LED LINEAR LIGHTBAR

PRODUCT DESCRIPTION

Architectural LED Linear Lightbar is a 9", 16", 24" or 32" WHITE FINISH, rigid and unobtrusive (only 1, 3/16" thickness) dimmable LED Lightbar that utilizes a dense array of strategically placed LEDs. Bars can be interconnected in series from one 120vac power feed. Only 3.5w for the 9", 6.8W for 18", 9W for 24", 12.4W for 36", and 16.7W for 48", 50,000 hour LED life. Each bar has an integral rocker switch. Designed for cove lighting, commercial and architectural applications. Frosted lens assures an even glow over the length of the fixture with virtually no visible diode imaging.

PRODUCT SPECIFICATIONS

Construction: is a uniquely designed, extruded aluminum vessel with clear polycarbonate lensing on/ off rocker switch. Includes mounting clips and screws and bar to bar connector in the package. All other accessories sold separately**

Electrical: Rated at only 4.2 watts per foot.

Color Temperature: 2700K, 3000K, 4000K

Power : 120VAC

Dimming: with standard leading edge triac dimmer switches


Mounting: 2 mounting clips with screws provided.

Flexible Connectors: Rigid lightbar to lightbar connector supplied (SLD-1). See chart below for other options. All other connectors sold separately.

Listing: cCSAus Energy Star

Connectors and Accessories

SLD-1	Bar to Bar Connector
SLD-C6	6' cord and plug
SLJ-12	12" flexible bar to bar connector
SLJ-24	24" flexible bar to bar connector
SLJ-36"	36" flexible bar to bar connector
SLJ-6	6" flexible bar to bar connector
SLJR-HSW	Junction box for hardwire
SLD-HW-72	Bar to power lead whip 72"

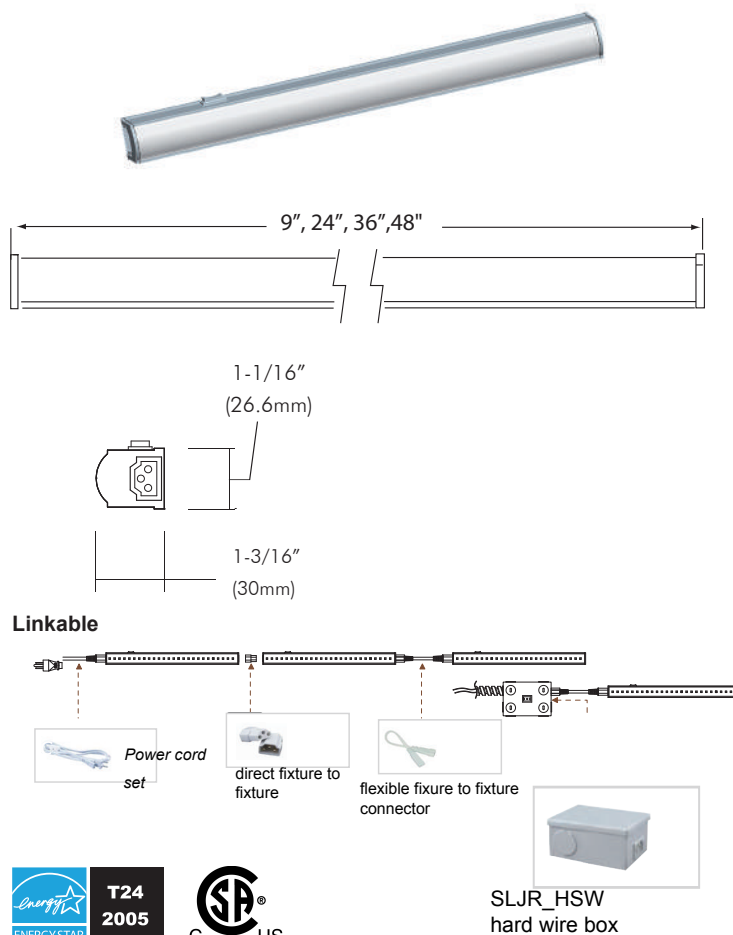

Model Number	Length	Color*	LED Wattage	Lumens / Bar	Finish	LED Life
SLCB-9-27	9"	2700K	3.5W / bar	280	WHITE	50,000 HRS
SLCB-18-27	18"	2700K	6.8W / bar	530	WHITE	50,000 HRS.
SLCB-24-27	24"	2700K	9W / bar	685	WHITE	50,000 HRS.
SLCB-36-27	36"	2700K	12.4W / bar	930	WHITE	50,000 HRS.
SLCB-48-27	48"	2700K	16.7W / bar	1230	WHITE	50,000 HRS.
SLCB-9-30	9"	3000K	3.5W / bar	280	WHITE	50,000 HRS
SLCB-18-30	18"	3000K	6.8W / bar	530	WHITE	50,000 HRS.
SLCB-24-30	24"	3000K	9W / bar	685	WHITE	50,000 HRS.
SLCB-36-30	36"	3000K	12.4 W / bar	930	WHITE	50,000 HRS.
SLCB-48-30	48"	3000K	16.7W / bar	1230	WHITE	50,000 HRS.
SLCB-9-40	9"	4000K	3.5 W / bar	280	WHITE	50,000 HRS
SLCB-18-40	18"	4000K	6.8W / bar	530	WHITE	50,000 HRS.
SLCB-24-40	24"	4000K	9W / bar	685	WHITE	50,000 HRS.
SLCB-36-40	36"	4000K	12.4W / bar	930	WHITE	50,000 HRS.
SLCB-48-40	48"	4000K	16.7W / bar	1230	WHITE	50,000 HRS.