

AimLite

P14LR

LED IC PANEL LIGHT



NEW

**120-347V
DRIVER**

YOUR CHOICE OF 3 SIZES AND 4 COLOUR TEMPERATURES

 **1'x4'**
30.5 cm x 122 cm

 **2'x2'**
61 cm x 61 cm

 **2'x4'**
61 cm x 122 cm

 **3000K**




 **3500K**

 **4000K**

 **5000K**



CONFIGURATIONS

	1'x4'	P14LR-1LA2-32/30K	4513 lumens (40W)
		P14LR-1LA2-32/35K	4400 lumens (40W)
		P14LR-1LA2-32/40K	4400 lumens (40W)
		P14LR-1LA2-32/50K	4400 lumens (40W)
	2'x2'	P14LR-2LA2-32/30K	4572 lumens (40W)
		P14LR-2LA2-32/35K	4400 lumens (40W)
		P14LR-2LA2-32/40K	4600 lumens (40W)
		P14LR-2LA2-32/50K	4600 lumens (40W)
	2'x4'	P14LR-4LA1-32/30K	6747 lumens (60W)
		P14LR-4LA1-32/35K	6600 lumens (60W)
		P14LR-4LA1-32/40K	6600 lumens (60W)
		P14LR-4LA1-32/50K	6600 lumens (60W)

FEATURES

- Colour consistency (SDCM) is 3 step MacAdam ellipse
- IC Rated
- 120-347V electronic driver with 0-10V dimming
- Estimated lifespan of over 50,000 hours to L70
- Low cost installation due to user friendly design
- White finish aluminum frame





P14LR


Optional drywall, surface and suspension kits available



standard
integrated
earthquake clips

5 layer light guide for better
uniformity and anti-yellowing

- Cover
- UV foam cotton
- Reflective paper
PET material, 95% reflectance, anti-erosion,
oxidation resistance, no color fading over time
- Light guide
3mm MITSUBISHI LIGHT GUIDE PLATE
- Diffuser plate
Polysterene (over 90% transmittance)
- Aluminum frame and PCB

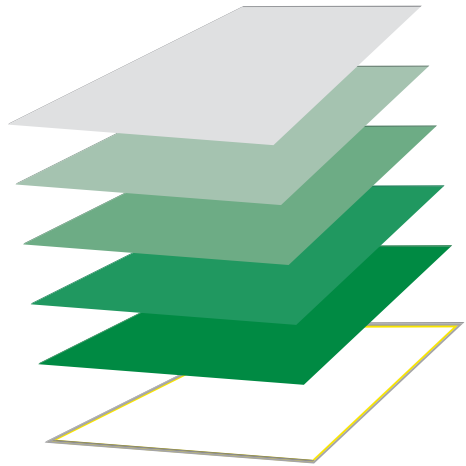

**SUPER BRIGHT
ENERGY EFFICIENT
ENVIRONMENTALLY FRIENDLY**

