

OWP-FC-201-LED

LED Medium Full Cut-Off Wall Pack Series

up to 61 Wattage / up to 6000 Lumens

Catalog Number:

Project Name:

Note:

Type:




APPLICATIONS:

This rugged medium size full cut-off LED wall pack provides long lasting, energy efficient lighting with a variety of options to customize fixture performance to the required task. Easily mounts to building and is ideal for industrial, educational, multi-family, institutional, and government applications.


FEATURES:

- Full cut-off and compliance to Dark Sky requirement
- Lumen output from 4900-6900lm with efficacy up to 115 lm/W
- 43W-63W power consumption, to replace 150W-250W MH
- Type II distribution with frosted tempered flat glass integrated lens
- Operating temperature is -40°C to 50°C (-40°F to 122°F)
- Dimmable
- UL/cUL wet location
- DLC qualified**

DIMENSION:

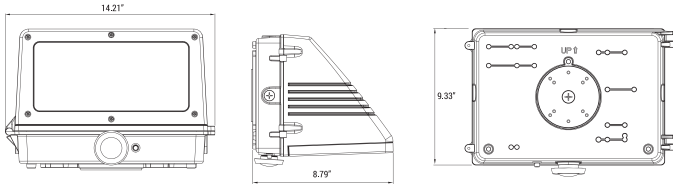

PHOTOMETRICS:

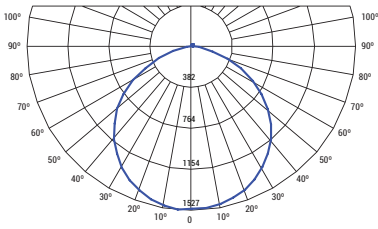

B	U	G
2	1	1

SPECIFICATIONS:

LUMENS	4900 / 6900 lumens
WATTAGE	43W / 63W (According to DLC Listing)
CCT	41K-50K
CRI	80
LIGHT EFFICIENCY	Up to 115 lumens/watt
VOLTAGE	120-277 VAC
POWER FREQUENCY	50/60 Hz
FINISH	Bronze
APPLICABLE ENVIRONMENT	Dry/Damp/Wet location
WORKING TEMPERATURE	-40°C to 50°C



Ordering Guide > Example: OWP-FC-201-LED-6000L-MVOLT-40K-BZ

OWP-FC-201-LED				
SERIES	PERFORMANCE	VOLTAGE	CCT	FINISH
OWP-FC-201-LED	4000L - 4900 lumens 6000L - 6900 lumens	MVOLT - 120-277V	40K - 4000K 50K - 5000K	BZ - Bronze

* For more lumen package option, consult factory

* Available with 347V

* For more CCT option, consult factory

** DesignLights Consortium® (DLC) qualified product. Not all versions of this product may be DLC qualified. Please check the DLC Qualified Products List at www.designlights.org to confirm which versions are qualified.

XXX		
B	U	G
0	0	0



Submittal form is available @ www.oraclelighting.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

Issued-B1118-Rev. 1