



### PRODUCT DESCRIPTION

A high output, wet location flexible 120V plug-in LED linear ribbon for architectural coves, indoor steps, bannisters, exterior recesses and other constructs where even, energy saving LED illumination is specified. Available in a 164 ft. reel.

5 year warranty. Do not submerge.

Custom cuts available - consult factory.

PROJECT	TYPE
CATALOG NUMBER	

### FEATURES

- 120VDC operation that does not require a remote power supply or driver.
- Wet location - IP67
- Utilizes high output 90+CRI SMD5360 diodes
- Diodes mounted to flexible copper buss
- Ribbon encased in water resistant clear acrylic, flexible sheath
- Dimmable with ELV dimmers
- Available on 164 foot reels
- Available with connectors and end caps
- Cuttable every 19"
- Maximum run: 164 feet
- Uses mounting clips or mounting channel

### ELECTRICAL


- 120VDC
- Only 2.6W per foot
- 120VAC with DC connector
- 50,000 hour LED life

### OPTICS


- 3000K or 4000K
- Up to 293 lumens per foot
- 90+ CRI

### LABEL

- cETLus
- IP67
- Conforms to UL94V-0, UL746C F(1)

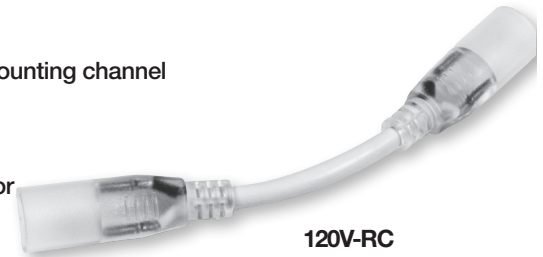

### DIAGRAM

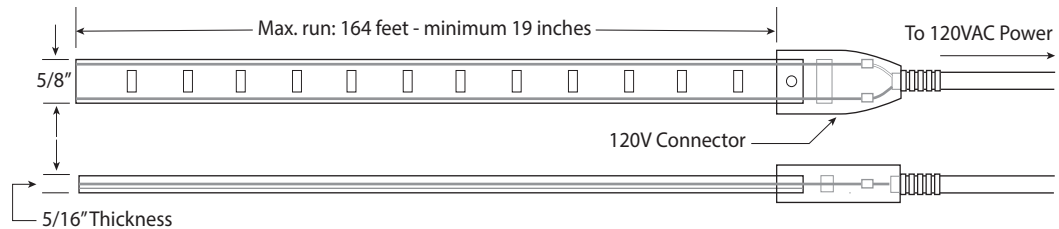

### ORDERING INFORMATION

Catalog No.	Length	LED Wattage	Lumens per Foot	Color Temp.*	LED Life
GM-120VHO164-30	164 FT.	2.6W / FT.	270	3000K	50,000 hrs.
GM-120VHO164-40	164 FT.	2.6W / FT.	293	4000K	50,000 hrs.

\* Kelvin temperature (color) ± 200K

### CONNECTORS AND MOUNTING CHANNELS

Catalog No.	Description
120V-PC	POWER CONNECTOR W/ POLARIZED FUSED PLUG, 24"
120V-PC-H	HARDWIRE POWER CONNECTOR
120V-RC	RIBBON TO RIBBON CONNECTOR WITH PINS 6"
120V-EC	END CAPS, BAG OF 10
120V-MC	MOUNTING CLIPS, BAG OF 10 (recommended 1 per foot minimum)
120V-CHL-P	39" PLASTIC MOUNTING CHANNEL - NO LENS