




WHITE &
CHROME



WHITE

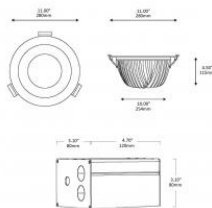

APX-LED-1010

10" HIGH PERFORMANCE APEX SERIES - 40W

Product codes

APX1010-3540-3K-WH : WHITE - 3K
 APX1010-3540-3KWCH : WHITE-CHROME 3K
 APX1010-3540-4K-WH : WHITE - 4K
 APX1010-3540-4KWCH : WHITE-CHROME 4K
 APX1010-3540-5K-WH : WHITE - 5K
 APX1010-3540-5KWCH : WHITE-CHROME 5K

This high performance LED recessed downlight comes with a pressure-fit spring clips for an easy installation. Integrated LED technology offers low-energy, long lasting performance with outstanding light outputs up to 4000 lumens.

The polycarbonate 60 degree reflector is designed for maximum reflection efficiency. The deep regressed diffuser is designed to eliminate the glare from the high powered LED. It is available with a White or Chrome reflector.

The body is constructed of die cast aluminum in 3", 4", 6", 8" & 10" trim sizes with a junction box manufactured in aluminum extrusion. Designed to replace existing CFL/PL, fluorescent or incandescent fixtures. Well adapted for any new, remodel or old commercial applications. For easy and quick installation, the unit comes with pressure-fit spring clips, quick connect wire connectors. It is IC and damp rated.

It features a 0-10V dimmable driver (120-277V).

Données techniques

Cutting hole	10.00" (254.0 mm)
Beam Angle	60° ± 1/2
Color Temperature	3K / 4K / 5K
Mounting Plate	MPHB-1000
CRI	>80
Voltage	120-277V
Dimmable	0-10V DIM
Dimmable	120V / 277V (0-10V)
Bulb Life	45,000hrs
Light Output - Lumen	4000LM
Operating Temperature	-40°C + 40°C