



# Energy Saver Outdoor

## EL/O 14W PRISMA 6/1

Looking for an energy saver that does not look like one? The Philips EnergySaver Outdoor family provides energy efficient lighting options that don't just provide similar light as your standard incandescent light bulb. Available in reflector flood, bug away, and post varieties. Try the Philips EnergySaver Outdoor family of products and see how they truly provide advanced lighting designed around your needs.

### Product data

General Information	
Cap-Base	E26 [ Single Contact Medium Screw]
Life with 3 Hour Per Day Use	9.1 a

Light Technical	
Color Code	827 [ CCT of 2700K]
Luminous Flux (Nom)	840 lm
Luminous Flux (Rated) (Nom)	840 lm
Color Designation	Warm White (WW)
Lumen Maintenance 2000 h (Nom)	80 %
Lumen Maintenance 5000 h (Nom)	70 %
Chromaticity Coordinate X (Nom)	459
Chromaticity Coordinate Y (Nom)	412
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (Rated) (Nom)	60 lm/W

Operating and Electrical	
Input Frequency	50 or 60 Hz


Power (Rated) (Nom)	14 W
Lamp Current (Nom)	205 mA
Power Factor (Nom)	0.55
Voltage (Nom)	110-127 V

Approval and Application	
Estimated Energy Cost Per Year	1.69 \$

Product Data	
Order product name	EL/O 14W PRISMA 6/1
EAN/UPC - Product	046677407780
Order code	929689942501
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929689942501
Net Weight (Piece)	0.118 kg

## Energy Saver Outdoor

### Dimensional drawing

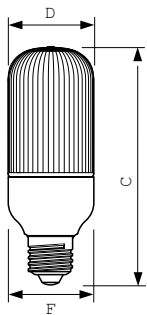

Product	D (max)	C (max)	F (max)
EL/O 14W PRISMA 6/1	51 mm	136.8 mm	50.5 mm

Ambiance 14W/827 E26 110-127V 50/60Hz PR

