

Device Boxes

Stainless Steel Wall Plates


IBERVILLE®

General Usage

Toggle Switch



CI97071

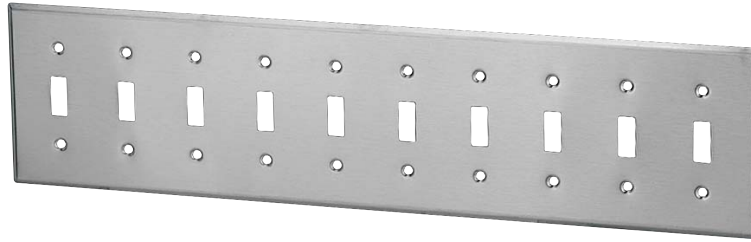

CI97080

1 gang to 10 gangs

Duplex Receptacle



CI97101



CI97102

Blank Box Mounting (3.281")




CI97011

GFCI / Decora



CI97401

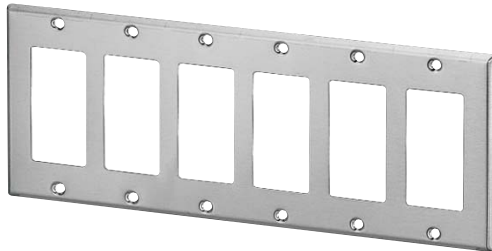


CI97406

1 gang to 6 gangs

Blank Device Mounting (2.375")



CI97121

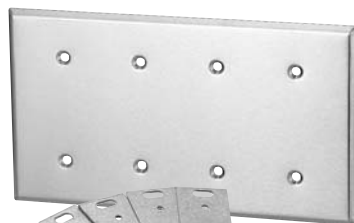


CI97124

1 gang to 4 gangs

Combination Switch / Receptacle



CI97532

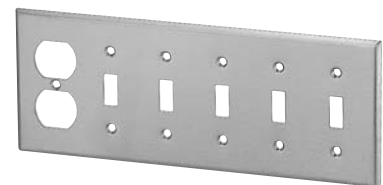

CI97573

2 gangs to 7 gangs

Device Boxes

Stainless Steel Wall Plates

IBERVILLE®

Specialty Usage

* Telephone



* CI97181

3/8" opening.



* CI97191

5/8" opening.

Emergency



CI6851-RF

ON / OFF

Single Receptacle



CI97091

1-13/32" diameter.

GFCI Conversion Kit



BC97002

For 4" square boxes.

347 Volt Toggle

For 1204 Series



CI6851-HV



CI6854-HV

1 gang to 4 gangs

For MBD / MBS Series



CI6851-HV



CI97074-HVR

1 gang to 4 gangs

347 Volt Blank

For 1204 Series



CI97151-HV



CI97154-HV

1 gang, 2 gangs and 4 gangs

For MBD / MBS Series



CI97151-HV



CI97154-HVR

1 gang, 2 gangs and 4 gangs



* Not applicable.




Device Boxes

Stainless Steel Wall Plates


IBERVILLE®

Dimensions


Standard Wall Plate

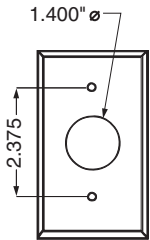


CI97091

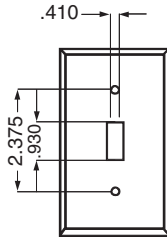


CI97071

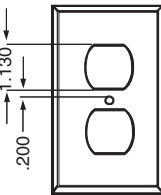


CI97101

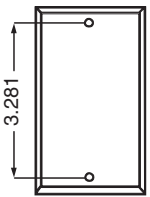

CI97011

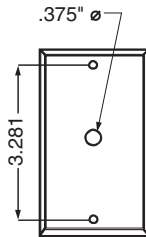


* CI97181

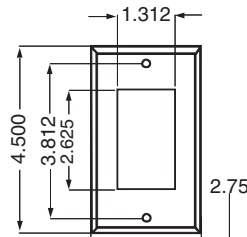


CI97401


Mounting Hole Spacings

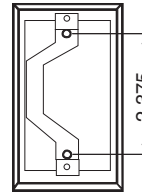


Device Mount

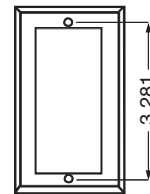

Box Mount

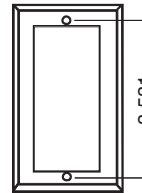


HV Box Mount

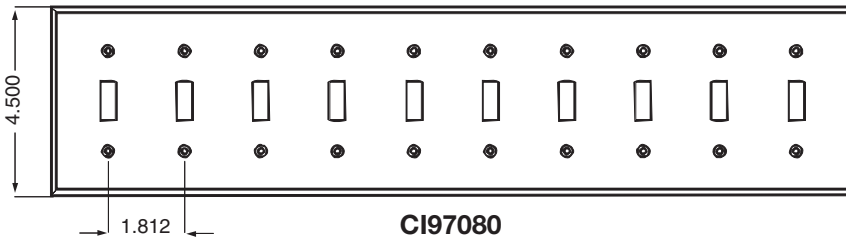


CI97080


347 Volt Wall Plate

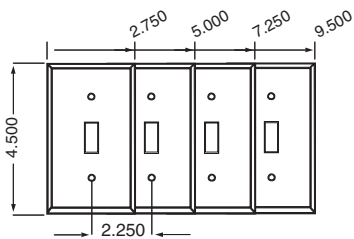


CI6851-HV to CI6854-HV

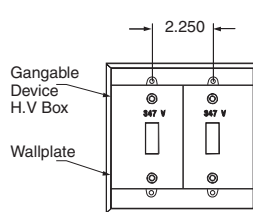

CI6852-HV

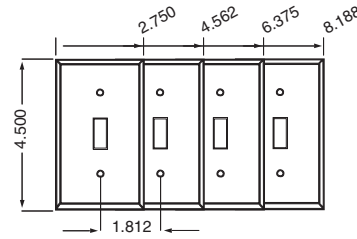

CI97072-HVR to CI97074-HVR

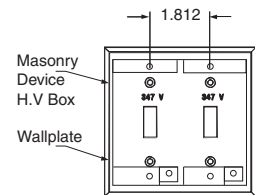

CI97072-HVR

Dimensions are in inches.

SP® * Not applicable.



Device Boxes

Stainless Steel Wall Plates

IBERVILLE®

Selection Guide

DESCRIPTION	1 GANG	2 GANGS	3 GANGS	4 GANGS	5 GANGS	6 GANGS	7 GANGS	8 GANGS	9 GANGS	10 GANGS
Toggle Switch†	CI97071	CI97072	CI97073	CI97074	CI97075	CI97076		CI97078	CI97079	CI97080
Duplex Receptacle†	CI97101	CI97102								
Blank Boxes										
Mounting 3.281"†	CI97011	CI97012	CI97013	CI97014						
Blank Device										
Mounting 2.375"†	CI97121	CI97122	CI97123	CI97124						
GFCI / Decora†	CI97401	CI97402	CI97403	CI97404	CI97405	CI97406				
GFCI Conversion Kit†		BC97002								
Combination										
Switch / Receptacle†		CI97532			CI97563	CI97573				
15 AMP Receptacle†	CI97091									
Telephone 3/8" Opening	* CI97181									
Telephone 5/8" Opening	* CI97191									
Emergency On / Off†	CI6851-RF									
347 Volt Toggle for 1204 Series	CI6851-HV	CI6852-HV	CI6853-HV	CI6854-HV						
347 Volt Blank for 1204 Series	CI97151-HV	CI97152-HV		CI97154-HV						
347 Volt Toggle for MBD and MBS Series	USE CI6851-HV	CI97072-HVR	CI97073-HVR	CI97074-HVR						
347 Volt Blank for MBD and MBS Series	USE CI97151-HV	CI97152-HVR		CI97154-HVR						

Technical Specifications

Type 430 Stainless Steel

- › 16% chrome.
- › Corrosion resistant.
- › Recommended for industrial, commercial and institutional applications.
- › Supplied with nickel plated brass screws.
- › 1 to 3 gang — Vertically Brushed.
- › 4 gang and up — Horizontally Brushed.

SP * Not applicable. † UL