

Type: _____
 Project/Location: _____
 Contractor: _____
 Prepared By: _____
 Date: _____
 Model No.: _____

EF9-BLD Series

“Built-in” micro LED lamps remote fixture



FEATURES

- 6 to 12V, 3W LED each head
 - Fire-retardant thermoplastic
 - 300° rotation
 - CSA certified to C22.2 No. 141
- See warranty details at: www.tnb.ca/en/brands/emergi-lite

TYPICAL SPECIFICATIONS

Lamp head and stem shall be injection molded, impact resistant, flame retardant thermoplastic.
 Fixture shall be supplied with a canopy for installation on any four inch octagon box.
 The remote unit shall be the **Emergi-Lite®** model: _____.




WIRE GUARDS

460.0029-E	Wall ceiling Mount
------------	--------------------

DIMENSIONS

Dimensions are approximate and subject to change.

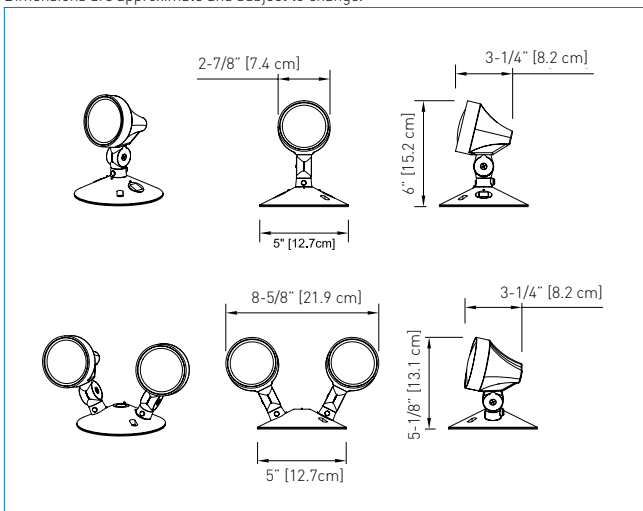

ORDERING INFORMATION

SERIES	NUMBER OF HEAD	LAMP TYPE
EF9= Plastic built-in LED	1= Single head 2= Double heads	BLD= Plastic built-in LED, 6V / 12V, 3W each

EXAMPLE: EF9BLD