

SWN

“NOAH” WET LOCATION ANTI VANDAL REMOTE

Single or double

6V, 12V & 24V lamps in LED & Quartz

The SWN series of wet location anti vandal remotes is designed to perform in extreme environments. The single or double lamp assemblies are completely protected from the elements within a fully gasketed polycarbonate housing. Available in 6V, 12V or 24V models, utilizing quartz halogen or LED (bi-pin based) lamps.

FEATURES AND SPECIFICATIONS

• **Electrical and circuitry**

- 6VDC, 12VDC or 24VDC
- Quartz halogen lamps - bi-pin based
- LED lamps - bi-pin based

• **Mechanical**

- Polycarbonate enclosure is fully gasketed around lens and canopy to prevent water infiltration
- Stainless steel tamper proof screws and bits
- Wet location
- Lamps are fully adjustable
- Fully gasketed housing
- Available in white and black
- Universal spider knockout pattern stamped into backplate for junction box mounting



• **Approvals**

- CSA Certified to C22.2 #141-15
- CSA Certified type 2, 3, 3R, 4, 4X, 5, 12 or 12K
- CSA Certified to NSF 2
- IP66

• **Compliance**

- Meets requirements of ICES-005

DIMENSIONS

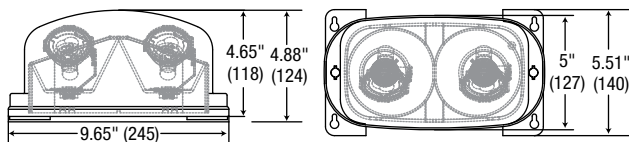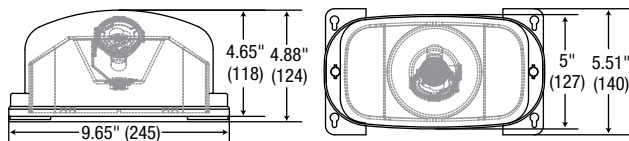

Project: _____
 Type: _____
 Catalogue #: _____
 Drawn by: _____
 Date: _____



OVERVIEW

Light source	LED or Quartz halogen
DC voltage	6VDC, 12VDC or 24VDC

ORDERING GUIDE - LED

Series	Nbr of heads	Voltage	Wattage	Lamp type	Colour
SWN	1 - Single head 2 - Double head	06-24 - 6VDC to 24VDC operational	4W - 4 watts	LR - LED	BK - Black WH - White
			5W - 5 watts	LA - LED	
	12-24 - 12VDC to 24VDC operational	6W - 6 watts	LA - LED		
		7W - 7 watts			

ORDERING GUIDE - INCANDESCENT

Series	Nbr of heads	Voltage	Lamp type	Colour
SWN	1 - Single head 2 - Double head	06 - 6VDC 12 - 12VDC 24 - 24VDC	See lamp selection chart	BK - Black WH - White

INCANDESCENT LAMP SELECTION

	6 Volts	12 Volts	24 Volts
Quartz halogen	08WQ, 10WQ	08WQ, 10WQ, 12WQ	10WQ, 12WQ

Comments

All products are subject to change or may be discontinued any time without notice.