

Single-Service Round Floor Boxes




Protection from
water, dirt, and
debris.

The 880 Series Floor Box provides an excellent solution for the low density power or communication requirements in open space areas. The 880 Series brings the power or communication service directly to the workstation. The 880 Series comes in a cast iron version for on grade applications and an economical stamped steel version for above grade applications. The 880 Series is supported by one of the most complete lines of brass, brushed aluminum, and nonmetallic activations in the industry. Some applications for the 880 Series Floor Box are retail facilities, commercial offices, hotels, and financial institutions.



880 Series Steel and Cast-Iron Floor Boxes.

Features & Benefits

- **TopGuard protection.** An integral design which keeps out  water, dirt, and debris from the power or communication compartments. Whenever you see the TopGuard protection icon applied to any Wiremold product, you will know that the product meets and exceeds the new UL scrub water exclusion requirement.
- **UL Listed to U.S. and Canadian safety standards for tile, terrazzo, and the future UL requirements under UL514A and UL514C for the scrub water exclusion test for carpet and wood floors. This future requirement takes effect June, 2003.**
- **Snap down ring assembly for steel floor boxes.** Labor saver.
- **Fully adjustable box.** Can adjust before and after concrete pour. Lower installed cost.
- **Handles single and duplex devices.** Economical solution for low density power requirements.
- **All 895 and 896 Cover Plates fit 885B, 886B, 887B, and 889B Floor Boxes.** More activation options to meet any decor.
- **Two different depths.** Accommodates various pour depths and wiring capacity requirements.

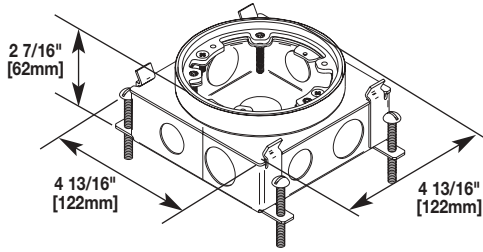
Steel Floor Box Order Information

Catalog No./Item

Description/Specifications

885B

Floor Box – Stamped steel, shallow single-service.




TECHNICAL SPECIFICATIONS

Class	Catalog No.	Adjustment		Capacity Cu In [484ml]	Knockouts or Conduit Openings
		Before the Pour [44mm]	After the Pour [12.7mm]		
Concrete-Tight (Steel)	885B	1 3/4"	1/2"	29.5 [484ml]	Four Sides – (1) 1/2" [12.7mm] (1) 3/4" [19.1mm] Bottom – (2) 1/2" [12.7mm] (2) 3/4" [19.1mm]

886B

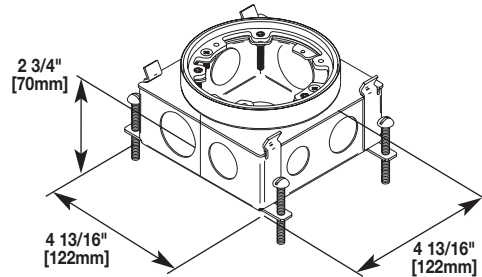Floor Box – Stamped steel, deep single-service.



TECHNICAL SPECIFICATIONS

Class	Catalog No.	Adjustment		Capacity Cu In [639ml]	Knockouts or Conduit Openings
		Before the Pour [44mm]	After the Pour [12.7mm]		
Concrete-Tight (Steel)	886B	1 3/4"	1/2"	39 [639ml]	Two Sides – (1) 1/2" [12.7mm] (1) 3/4" [19.1mm] Two Sides – (1) 3/4" [19.1mm] (1) 1" [25mm] Bottom – (2) 1/2" [12.7mm] (2) 3/4" [19.1mm]

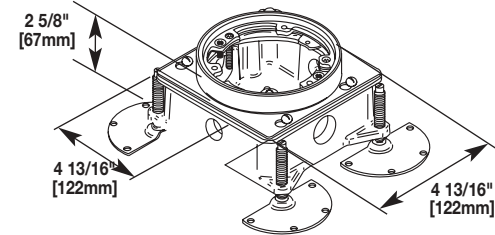
Cast-Iron Floor Box Order Information

Catalog No./Item

Description/Specifications

887B

Floor Box – Cast-iron, shallow single-service.




Technical Specifications

Class	Catalog No.	Adjustment		Capacity Cu In [405ml]	Knockouts or Conduit Openings
		Before the Pour [51mm]	After the Pour [12.7mm]		
Watertight (Cast-Iron)	887B	2"	1/2"	24.7 [405ml]	Two Sides – (1) 1/2" [12.7mm] Two Sides – (1) 3/4" [19.1mm]

889B









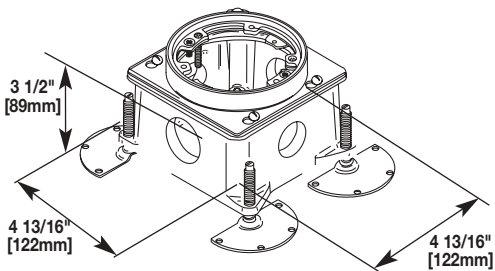

Floor Box – Cast-iron, deep single-service.



Technical Specifications


Class	Catalog No.	Adjustment		Capacity Cu In [665ml]	Knockouts or Conduit Openings
		Before the Pour [51mm]	After the Pour [12.7mm]		
Watertight (Cast-Iron)	889B	2"	1/2"	40 [665ml]	Two Sides – (1) 1" [25mm] Two Sides – (1) 1 1/4" [19.1mm]

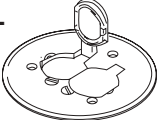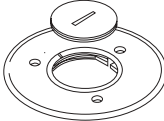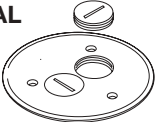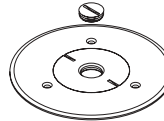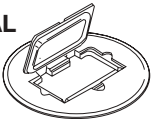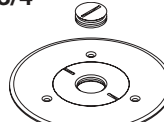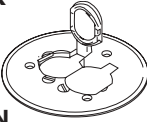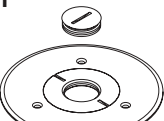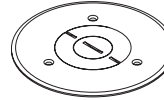Cover Plates for 880 Series Floor Boxes


Catalog No./Item	Description/Specifications	Catalog No./Item	Description/Specifications
895 895TCAL	 Brass/Brushed Aluminum Duplex Cover Plate – With flip lids. 5 1/2" [140mm] diameter for carpet.	896CK	 Brass Cover Plate – Communication or power with 2 1/4" [57mm] threaded opening. 5 1/2" [140mm] diameter for carpet.
895T 895TAL	Brass/Brushed Aluminum Duplex Cover Plate – With flip lids. 4 1/4" [108mm] diameter for tile.	896TCK	Brass Cover Plate – Communication or power with 2 1/4" [57mm] threaded opening. 4 1/4" [108mm] diameter for tile.
895SP 895SPCAL	 Brass/Brushed Aluminum Cover Plate – With two screw plug openings.* 5 1/2" [140mm] diameter for carpet.	896CK-1/2 896CKAL-1/2	 Brass/Brushed Aluminum Cover Plate – With 1/2" [12.7mm] opening. 5 1/2" [140mm] diameter for carpet.
895TSP 895TSPAL	Brass/Brushed Aluminum Cover Plate – With two screw plug openings.* 4 1/4" [108mm] diameter for tile. <i>*Screw plug openings are 1 1/2" [38mm] – 16 tapped openings.</i>	896TCK-1/2 896TCKAL-1/2	Brass/Brushed Aluminum Cover Plate – With 1/2" [12.7mm] opening. 4 1/4" [108mm] diameter for tile.
895GFI 895GFICAL	 Brass/Brushed Aluminum Cover Plate – With GFI receptacle. 5 1/2" [140mm] diameter for carpet.	896CK-3/4	 Brass Cover Plate – With 3/4" [19.1mm] opening. 5 1/2" [140mm] diameter for carpet.
895TGFI 895TGFIAL	Brass/Brushed Aluminum Cover Plate – With GFI receptacle. 4 1/4" [108mm] diameter for tile.	896TCK-3/4	Brass Cover Plate – With 3/4" [19.1mm] opening. 4 1/4" [108mm] diameter for tile.
895P-BLK	 Duplex Cover Plate – Black polycarbonate with flip lids. 5 1/2" [140mm] diameter.	896CK-1	 Brass Cover Plate – With 1" [25mm] opening. 5 1/2" [140mm] diameter for carpet.
895P-BRN	Duplex Cover Plate – Brown polycarbonate with flip lids. 5 1/2" [140mm] diameter.	896TCK-1	Brass Cover Plate – With 1" [25mm] opening. 4 1/4" [108mm] diameter for tile.
895P-BRZ	Duplex Cover Plate – Bronze polycarbonate with flip lids. 5 1/2" [140mm] diameter.	896PCK-BLK	 Cover Plate – Black polycarbonate – communication or power. 5 1/2" [140mm] diameter.
895P-AL	Duplex Cover Plate – Aluminum polycarbonate with flip lids. 5 1/2" [140mm] diameter.	896PCK-BRN	Cover Plate – Brown polycarbonate – communication or power. 5 1/2" [140mm] diameter.
896*	 Brass Cover Plate – Communication or power with 2 5/8" [67mm] threaded opening. 5 1/2" [140mm] diameter for carpet.	896PCK-BRZ	Cover Plate – Bronze polycarbonate – communication or power. 5 1/2" [140mm] diameter.
896T	Brass Cover Plate – Communication or power with 2 5/8" [67mm] threaded opening. 4 1/4" [108mm] diameter for tile. <i>*Sold less abandon plug.</i>	896PCK-AL	Cover Plate – Aluminum polycarbonate – communication or power. 5 1/2" [140mm] diameter.

NOTE: All cover plates are furnished with gasket and three screws.

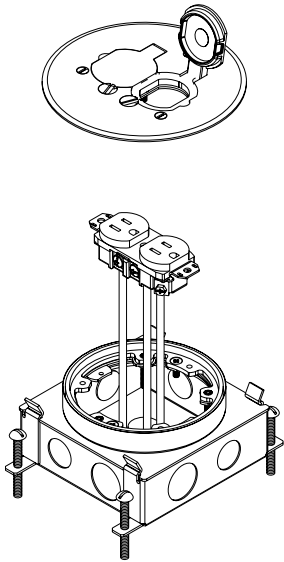
885 Series Floor Box Installations



885 Floor Box with 895 Cover

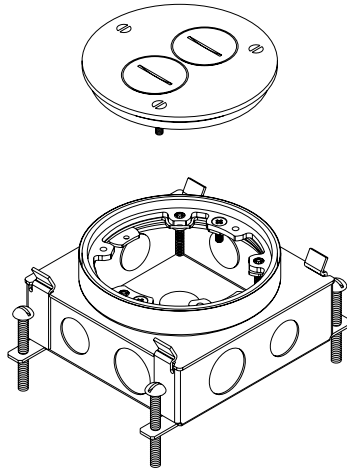

885B Floor Box with 895TSP Cover

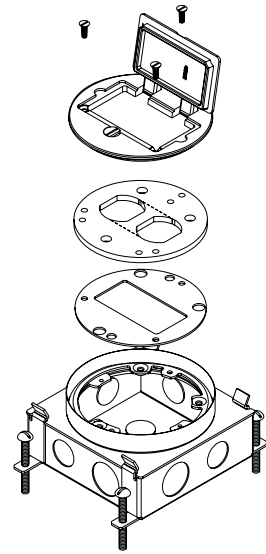

885B Floor Box with 895TGF1 Cover

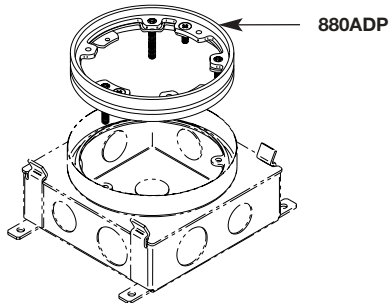
Retrofit Installations

Catalog No./Item

880ADP

Description/Specifications

Adjusting Ring – Used to retrofit existing installed floor boxes. Use with 885, 886, 887, and 889 Floor Boxes to accommodate 893/894 Series Covers.



885 Floor Box, Installed

To Wiremold.com 

Guide Form Specs
CAD Drawings Available

WIREMOLD

 legrand®

Wiremold / Legrand

U.S. and International:

60 Woodlawn Street • West Hartford, CT 06110

1-800-621-0049 • FAX 860-232-2062 • Outside U.S. 860-233-6251

Canada:

570 Applewood Crescent • Vaughan, Ontario L4K 4B4

1-800-723-5175 • FAX 905-738-9721

ED768R6 – Updated November 2006 – For latest specs visit www.wiremold.com

