


## Blank Plates -- Strap Mounted, Two Gang, 302/304 Stainless Steel

SS24

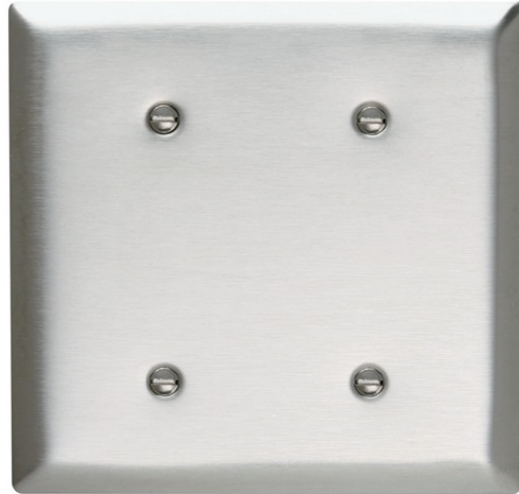

Smooth Metal Wall Plate 2gang Blank Strap Mounted 302/304 Stainless Steel



### features & benefits

- Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness.
- Brushed finish.
- This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion.
- Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes.
- Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

### specifications

#### General Info

Size: Standard  
Type: Strap Mount  
Style: Blank Plate

#### Listing Agencies/Third Party Information

CSA Listing Info: Yes

CUL Listing No: No  
cULus: No  
cURus: No  
Federal Spec: No  
UL Listing No: Yes  
UN SPS C: 39121704  
UR: No

**Dimensions**

Weight: 0.24007

**Technical Information**

Material: 302/304 Stainless Steel  
Mounting: strap mount  
Capacity: 2-gang

**Buy American Act Compliance**

Country of Origin: UNITED-STATES-OF-AMERICA  
Buy American Act Status: Buy American Act Compliant