


## Duplex Receptacle Openings, Two Gang, 430 Stainless Steel

SL82

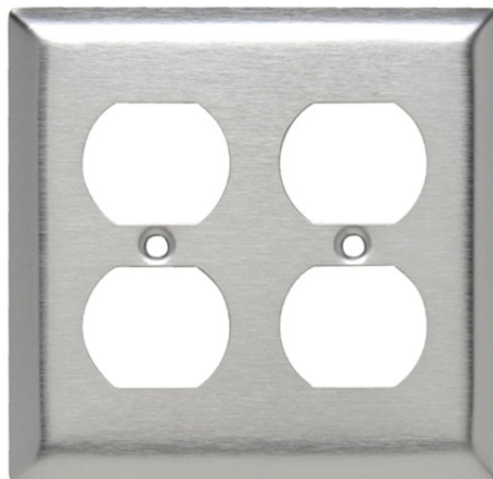

Smooth Metal Wall Plate 2gang Duplex 430  
Stainless Steel

### features & benefits



- Type 430 Stainless Steel, magnetic: .032" nominal thickness.
- Brushed finish.
- Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.
- Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.
- Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes.
- Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.
- For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

### specifications

#### General Info

Size: Standard  
Type: Duplex

#### Listing Agencies/Third Party Information

CSA Listing Info: Yes  
CUL Listing No: No

cULus: No  
cURus: No  
Federal Spec: No  
UL Listing No: Yes  
UN SPS C: 39121704  
UR: No

### **Dimensions**

Weight: 0.15988

### **Technical Information**

Material: 430 Stainless Steel  
Capacity: 2-gang

### **Buy American Act Compliance**

Country of Origin: UNITED-STATES-OF-AMERICA  
Buy American Act Status: Buy American Act Compliant