 


FUW-L

3 IN 1 LED FLOOD LIGHT/WALL PACK

22W and 40W (1830 lumens and 3293 lumens)



Approvals:
cULus listed
Suitable for wet locations



quick
ship



Conduit mounting
shown

Surface mounting
shown


DESCRIPTION

The newly designed and versatile FUW-L is a highly efficient LED Flood Light and wall mount luminaire. This fixture is supplied with a photocell (120V), a wall bracket (for surface mounting), a wiring box (for feed-through mounting), and a 1/2" adjustable fitter that mounts on a standard box. This fixture is best suited for entrances, underpasses, or anywhere controlled security lighting is required, as well as general lighting of grounds, and floodlighting of signs and building fronts. The FUW-L is made of tough die cast aluminum housing and is IP65 rated. This fixture also has the option of adding a slipfitter or trunion.

TECHNICAL SPECIFICATIONS

- Die cast aluminum housing
- Integrated photocell (120V)
- Bronze UV resistant powder coat finish
- Input voltage: 120V AC standard (208-277V and 347V AC optional)
- High quality, long life LEDs
- Estimated lifespan of 50,000 hours
- 22W offers 1830 total lumens
- 40W offers 3293 total lumens
- 5000K colour temperature
- Low starting temperature of -40°C

DIMENSIONS

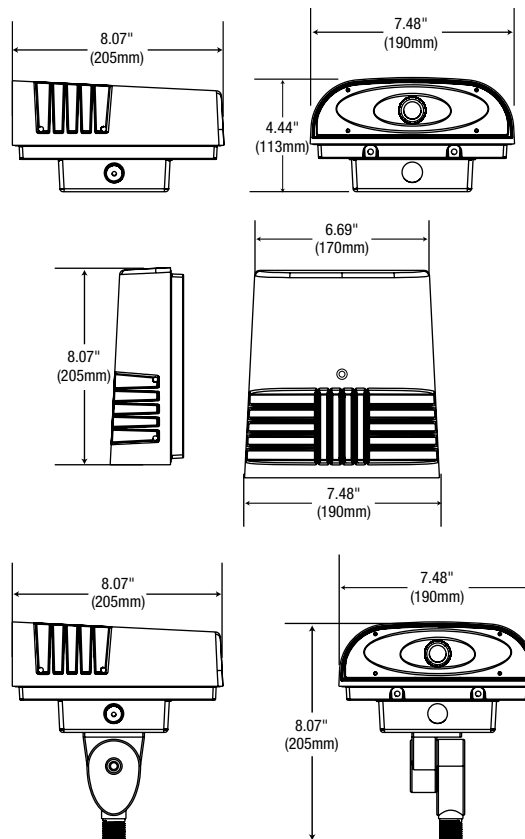

QUICK SHIP ORDERING GUIDE*

Part number	Wattage (W)	Lumens	Voltage (V)	Colour temperature	Efficacy (Lm/W)
FUW-LS1-A/50K/P	40	3293	120	5000K	82

* **QUICK SHIP:** Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.

ORDERING GUIDE

Series	Lamp type	Lumen package	Voltage	Colour temperature	Casting colour	Options
FUW	L - LED	S0 - 1830 Lumens (22W) S1 - 3293 Lumens (40W)	A - 120V (standard) G - 208-277V H - 347V	50K - 5000K	Blank - Bronze (standard) WH - White	P - 120V photocell (standard in 120V and 347V) P277 - 208-277V photocell A - Slipfitter TR - Trunion or Yoke mount