

SLG-2

PLASTIC COMPACT BATTERY UNIT 6VDC Output/120/347VAC Input



SP Approvals:
CSA Certified to C22.2 #141.15

DESCRIPTION

The SLG-2 series of plastic battery units provides an economical and versatile solution to emergency lighting needs all within a small, compact design. The SLG-2 series is a stand-alone battery unit (not capable of remote load connection) configured with 6VDC output and 30W of battery capacity for 30 minutes duration. Units can be fitted with a wide range of lamp head types and wattages.

CIRCUITRY


- 120/347VAC 60Hz Input, field selectable
- Solid state variable rate charger
- 6VDC emergency power output
- 30W battery capacity
- 30 minutes emergency battery duration standard
- Momentary push button test switch
- Pilot LED for AC ON status
- Fully automatic, current limited charger
- Short circuit protection
- Complete battery recharge in 24 hours
- Maintenance free, sealed lead acid battery

MECHANICAL

- High impact, UV stabilized, thermoplastic construction
- Low profile, canopy type design with extremely small total footprint
- Universal spider knockout pattern and keyhole mounting slots stamped into back of cabinet
- Unit "quick snaps" onto backplate for simple, speedy installation
- White color is standard

Note: Not intended for flush ceiling mount.

DIMENSIONS

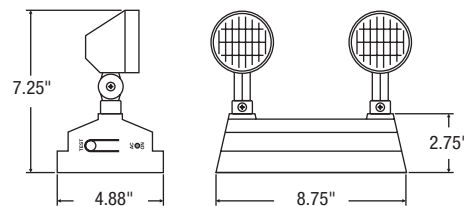

ORDERING GUIDE

Series	Voltage	Wattage	Lamp assembly	Lamp type	Color	Options†
SLG-2	06 - 6VDC	030 - 30W	0 - No lamp 1 - One lamp 2 - Two lamps	See lamp selection below	WH - White (standard)	WG - Wireguard

† For detailed options descriptions, please consult the options page.

LAMP SELECTION

6 Volts	
PAR18 - Small head or LED Lamp	
LED	3LJ, 4LJ
Quartz halogen	08Q, 10Q, 12Q
Tungsten	09T
PAR36 - Large head	
Quartz halogen	08Q, 10Q, 12Q
Tungsten	9T, 12T
Quartz sealed beam	08SBQ, 12SBQ
Tungsten sealed beam	08SBT, 09SBT