

L2WRN

LED SURFACE MOUNT WRAPAROUND



quick
ship



Not all products are qualified on the DLC QPL. To view our DLC qualified products, please consult the DLC Qualified Products List at www.designlights.org/search.



DESCRIPTION

Stanpro's L2WRN is ideally suited for residential and light commercial applications (utility rooms, stairways, restrooms, etc.) where uniform and efficient lighting is required.

HOUSING & FINISHING

The shallow body is made of die-formed cold rolled steel, post-painted high gloss white.

LENS

Prismatic acrylic frosted K-12 pattern (0.1 inch). Two lens retaining clips included to secure the lens tightly to the fixture.


SPECIFICATIONS

- 80+ CRI
- THD < 20%
- Power factor of > 0.90
- Estimated lifespan of over 50 000 hours to L70
- Suitable for damp locations
- 0-10V dimmable ready standard
- Meets requirements of ICES-005 issue 4 for class A products
- Ambient temperature: -20°C to +50°C

MOUNTING

Surface mounting (wall and ceiling).

DIMENSIONS

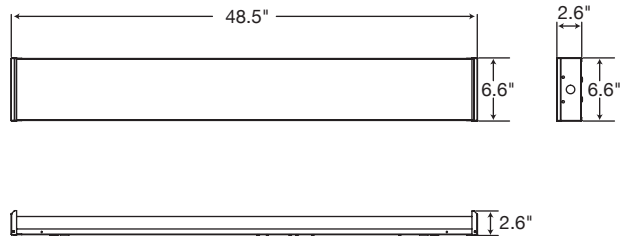

QUICK SHIP

Part Number	Size	Lumens	CRI	Voltage	Colour temperature	Stocking SKU
L2WRN-48-1	48 - 48"	4548 lumens (40W)	80	120-277V	40K - 4000k	✓

CONFIGURABLE ORDERING GUIDE

Series	Size	Lens	Lumens package delivered	CRI	Voltage	Colour temperature	Options
L2WRN	48 - 48"	BLANK - Frosted K12	045 - 4548 (40W)	80 - 80+	A - 120V W - 120-277V H - 347V	35K - 3500K 40K - 4000K 50K - 5000K	OSI - Occupancy sensor ODIM40 - Bi-level dimming 100% / 40% with OSI DIM2 - Line voltage dimming, driver 120V DALI 1 - Digital addressable lighting interface driver