







## Nonmetallic Strain Relief Connectors

Scepter Nonmetallic Strain Relief Connectors are supplied with all the components you need for a complete connection. The connector body, a selection of grommets accepting a range of cord dimensions, a sealing 'O' ring and metallic locknut are all supplied in one package. Available in 1/2" and 3/4" threaded hub and 3/4" PVC socket solvent weld configurations to accommodate a variety of applications.

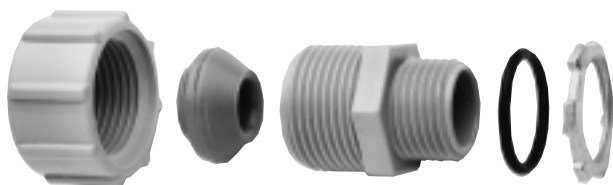
## Grommet Dimensions

	FROM	TO		FROM	TO
	W = .195" L = .450"	W = .285" L = .530"		Ø = .290"	Ø = .385"
	W = .220" L = .516"	W = .291" L = .565"		Ø = .405"	Ø = .500"
	Ø = .240"	Ø = .300"		Ø = .525"	Ø = .625"

Note: All grommets are supplied with TSRC10, TSRC15 & SRC15.

## Threaded Strain Relief Connector c/w O" Ring, Locknut & 6 Grommets

Size (inches)	Part Number	Product Code
1/2	TSRC10	077754
3/4	TSRC15	077756



## Strain Relief Connector c/w 6 Grommets

Size (inches)	Part Number	Product Code
3/4	SRC15	077985



## End Bells

Size (inches)	Part Number	Product Code
1/2	EB-10	077406
3/4	EB-15	077085
1	EB-20	077323
1 1/4	EB-25	077324
1 1/2	EB-30	077325
2	EB-35	077326
2 1/2	EB-40	077327
3	EB-45	077328
3 1/2	EB-50	077329
4	EB-55	077330
5	EB-60	077331
6	EB-65	077332



## End Caps

Size (inches)	Part Number	Product Code
1/2	CAP10	077421
3/4	CAP15	077422
1	CAP20	077423
1 1/4	CAP25	077424
1 1/2	CAP30	077425
2	CAP35	077426
2 1/2	CAP40	077427
3	CAP45	077428
3 1/2	CAP50	077429
4	CAP55	077430
5	CAP60	077431
6	CAP65	077432



## Poly Plugs

Size (inches)	Part Number	Product Code
2 - 2 1/2	PP3540	077433
3 - 3 1/2	PP4550	077434
4	PP55	077435
5	PP60	077436
6	PP65	077437

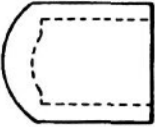


# Scepter Electrical Systems


UL Listed except where noted with \*

Description	Dimension (inches)	Part Number	Product Code	Std. Pkg.	Wgt/Pkg (lbs)	Price Per 100
-------------	--------------------	-------------	--------------	-----------	---------------	---------------

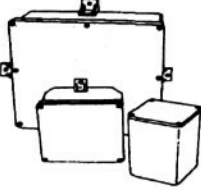
## End Caps - Solvent Weld

	1/2	* CAP 10	77421	200	8	\$ 135.16
	3/4	* CAP 15	77422	150	8	\$ 148.53
	1	* CAP 20	77423	100	10	\$ 160.42
	1 1/4	* CAP 25	77424	50	5	\$ 231.68
	1 1/2	* CAP 30	77425	40	8	\$ 303.07
	2	* CAP 35	77426	20	5	\$ 426.34
	2 1/2	* CAP 40	77427	15	6	\$ 912.04
	3	* CAP 45	77428	10	6	\$ 971.53
	3 1/2	* CAP 50	77429	10	8	\$ 1,457.22
	4	* CAP 55	77430	10	10	\$ 2,063.24
	5	* CAP 60	77431	12	10	\$ 2,306.95
6	* CAP 65	77432	10	10	\$ 3,156.55	

## Poly Plugs c/w Pulling Eye


	2 - 2 1/2	* PP3540	77433	176	11	\$ 117.92
	3 - 3 1/2	* PP4550	77434	200	34	\$ 199.73
	4	* PP55	77435	180	39	\$ 272.06
	5	* PP60	77436	100	26	\$ 363.36
	6	* PP65	77437	90	32	\$ 449.87

## Junction Boxes c/w Gasket and External Mounting Feet

	4 x 4 x 2	JB442	77659	15	9	\$ 1,454.28	
	NEMA Rated 1,2,3,4,4x,12,13, and UL Listed for Wet Locations	4 x 4 x 4	JB444	77696	10	9	\$ 2,398.93
	4 x 4 x 6	JB446	77669	8	9	\$ 2,765.78	
	5 x 5 x 2	JB552	77670	12	10	\$ 2,881.01	
	6 x 6 x 4	JB664	77697	15	28	\$ 2,936.76	
	6 x 6 x 6	JB666	77698	4	10	\$ 3,426.87	
	8 x 8 x 4	JB884	77664	4	16	\$ 5,540.65	
	8 x 8 x 7	JB887	77671	4	20	\$ 7,790.24	
	12 x 12 x 4	JB12124	77672	2	13	\$ 8,507.75	
	12 x 12 x 6	JB12126	77666	4	30	\$ 8,729.94	
	12 x 12 x 8	JB12128	77668	3	27	\$ 13,366.71	
	Unassembled bulk pack:	4 x 4 x 2	JB442	77699	45	27	\$ 1,454.12
4 x 4 x 2	JB442	77086	15	9	\$ 1,454.12		

## Flanged PVC Junction Boxes with Fiber Reinforced Safety Tread Cover

Price per 100

	6 x 6 x 4 1/4 D	* H664	77685	4	20	\$ 18,300.00
	6 x 6 x 6 1/4 D	* H666	77686	3	5	\$ 19,700.00
	8 x 8 x 4 1/4 D	* H884	77687	3	21	\$ 24,500.00
	8 x 8 x 7 1/4 D	* H887	77689	2	17	\$ 25,700.00
	8 x 8 x 7 1/4 D	* H887-A	77692	2	17	\$ 25,700.00

### Fabricated PVC Junction Boxes

Note: Boxes of any dimension are available. Price on request. Boxes fabricated to suit customers' specifications are not returnable. The order cannot be cancelled and boxes are not UL Listed.

## Index

Access Fittings	7, 8	Nonmetallic Vapor-Proof	
Access Pull Elbow	6	Incandescent Fixtures	19
Adapters	2, 17	Octagonal Box Extension Rings	15
Carpet Flanges	12	Octagonal Boxes	15
Cements	19	Pipe Straps	9
Couplings	2, 6	Poly Plugs	16
Cover Plates	14 - 15	Primers	19
Duct Elbows	22	Reducer Bushings	10
End Bells	18	Swedge Reducer Bushings	10
End Caps	16	Repair Couplings Sleeve	6
Expansion and Deflection		Service Entrance Fittings	8
Fittings Assemblies	17	Slip Meter Risers	17
Expansion Joints	17	Special Radius Elbows - Sch 40	20 - 21
F - Series Gang Boxes		Special Radius Elbows - Sch 80	21
- Single, Double, Triple	13	Standard Radius Elbows - Sch 40	3 - 4
Floor Box & Covers	11 - 12	Standard Radius Elbows - Sch 80	5
Junction Boxes	16	Strain Relief Connectors	10
Kwikon <sup>®</sup> ENT & Fittings	23 - 25	Threaded Round Boxes	15
Metal Cover Adapter Kit	11	Universal Leveling Ring Adapter	11
Meter Hubs	9	Vertical-Lok Spacers	18
Meter Offsets	9	Weatherproof Covers	14, 15

## Standards

PVC Electrical Fittings	UL 514B, 514C, & 651, NEMA TC - 2, 3
Junction Boxes	Rated NEMA 1, 2, 3, 4, 4x, 11, 12, 13
Kwikon ENT Tubing	UL Listed, NEMA TC - 13, Max 90°C Wire
Kwikon ENT Fittings	UL 514B, Concrete Tight, CSA G22.2, NO. 227.1

## Legend

c/w	complete with
UL	Underwriters Laboratory