


Industrial grade manual motor controllers


Product description

3-pole
40A, 600V/AC


Two-position, maintained contact, single throw, 3-pole, 3-phase

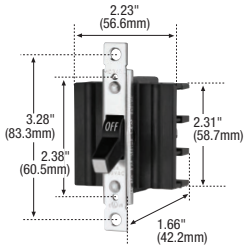

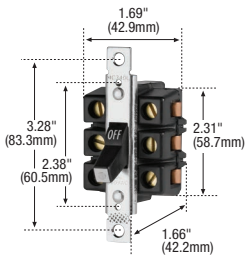

AHMC340C

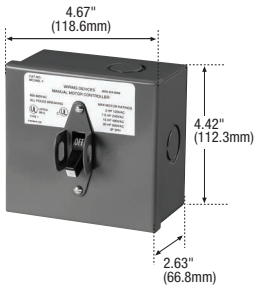

AHMC340L





AHMC340L-1

Rating A	V/AC	Description	Termination style	Max. AWG wire size	Catalog no.		
40	600	Switch only	Side wired	#8 AWG	<input type="checkbox"/> AHMC340C	•	•
		Switch in NEMA Type 1 enclosure	Side wired	#8 AWG	<input type="checkbox"/> AHMC340C-1	•	
		Switch in NEMA Type 3R enclosure	Side wired	#8 AWG	<input type="checkbox"/> AHMC340C-3	•	
		Switch only	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC340L	•	•
		Switch in NEMA Type 1 enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC340L-1	•	
		Switch in NEMA Type 3R enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC340L-3	•	

Horsepower rated for motor loads per UL508

	120V/AC	240V/AC	480V/AC	600V/AC
HP	3	7.5	15	20

Accessories for 40A manual motor controllers

Description	Catalog no.		
Empty enclosure, NEMA Type 1 single-gang	<input type="checkbox"/> AHN1GD	•	
Empty enclosure, NEMA Type 1 double-gang	<input type="checkbox"/> AHN1GD2	•	
Empty enclosure, NEMA Type 3R	<input type="checkbox"/> AHN3WD	•	
Wet-location plastic 1-Gang weather protective flush mount toggle switch cover	<input type="checkbox"/> S2983	•	
1-Gang, standards size 302/304 Stainless steel wallplate	<input type="checkbox"/> 93071	•	•



AHN1GD



AHN1GD2



AHN3WD



S2983



93071

Specification information: AHMC300 series: E-43

Compliances, specifications and availability are subject to change without notice.

 Indicates NAFTA compliant - Page Q-32

 RoHS compliant - Page Q-32