



## Industrial grade manual motor controllers

### Product description


2-pole & 3-pole  
60A, 600V/AC

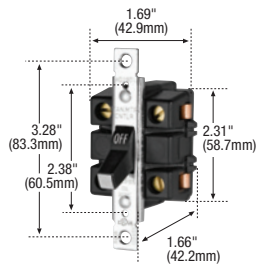

AHMC260L

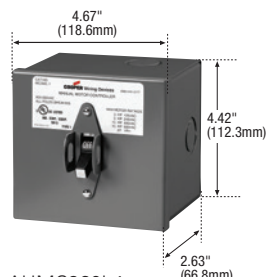

AHMC260L-1

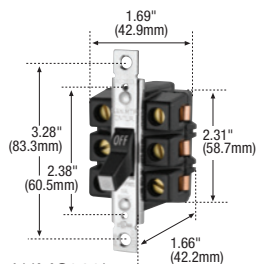

AHMC360L

### Two-position, maintained contact, single throw, 2-pole, single-phase

Rating A	V/AC	Description	Termination style	Max. AWG wire size	Catalog no.		
60	600	Switch only	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC260L	•	•
		Switch in NEMA type 1 enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC260L-1	•	
		Switch in NEMA type 3R enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC260L-3	•	

#### Horsepower rated for motor loads per UL508

	120 V/AC	240 V/AC	480 V/AC	600 V/AC
HP	3	5	15	15

### Two-position, maintained contact, single throw, 3-pole, 3-phase

Rating A	V/AC	Description	Termination style	Max. AWG wire size	Catalog no.		
60	600	Switch only	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC360L	•	•
		Switch in NEMA type 1 enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC360L-1	•	
		Switch in NEMA type 3R enclosure	Side wired box lug	#4 AWG	<input type="checkbox"/> AHMC360L-3	•	

#### Horsepower rated for motor loads per UL508

	120 V/AC	240 V/AC	480 V/AC	600 V/AC
HP	5	10	25	30

### Accessories for 60A manual motor controllers

Description	Catalog no.		
Empty enclosure, NEMA type 1 single-gang	<input type="checkbox"/> AHN1GD	•	
Empty enclosure, NEMA type 3R	<input type="checkbox"/> AHN3WD	•	
Wet-location plastic 1-gang weather protective flush mount toggle switch cover	<input type="checkbox"/> S2983	•	
Cast aluminum single gang 3-hole powder coated back box	<input type="checkbox"/> 1113	•	•
1-Gang, standards size 302/304 stainless steel wallplate	<input type="checkbox"/> 93071	•	•



AHN1GD



AHN3WD



S2983



1113



93071

Specification information: AHMC200 & AHMC300 series: E-45

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30