

J



SECTION

Straight blade receptacles


Hospital grade straight blade receptacles

Product description

2-pole, 3-wire grounding
15A, 250V/AC; 20A, 250V/AC
NEMA 6-15R, 6-20R

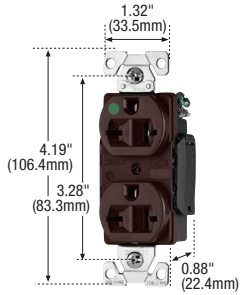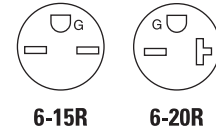

AH8400

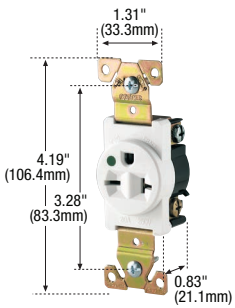

8410

Premium hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	🇺🇸	✓
15	250	6-15R	Duplex receptacle, back & side wire		V, W	□ AH8600__	•	•	•
			Single receptacle, back & side wire		V, W	□ 8610__	•	•	•
20	250	6-20R	Duplex receptacle, back & side wire		B, GY, RD, V, W	□ AH8400__	•	•	•
			Single receptacle, back & side wire		B, RD, V, W	□ 8410__	•	•	•

Accessories for hospital grade NEMA 6-15 & 6-20 receptacles

Description	Color suffix	Catalog no.	🇺🇸	✓
1-Gang standard size duplex receptacle nylon wallplate	V	□ 5132V	•	•
1-Gang mid-size duplex receptacle polycarbonate wallplate	LA	□ PJ8LA	•	



5132V



PJ8LA

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



Compliances, specifications and availability are subject to change without notice.

Specification information:
Premium HG receptacles: A-26
ArrowLink premium HG receptacles: A-30 & A-31

▶ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-9

🏠 Build-to-spec customizable devices - Page J-10

🇺🇸 Indicates NAFTA compliant - Page Q-32

✓ RoHS compliant - Page Q-32