



PRODUCT SEARCH

[HOME](#)[WHAT'S NEW](#)[SERVICE / SUPPORT](#)[WHERE TO BUY](#)[INSTRUCTION MANUALS](#)[CO](#)**TESTING & MEASUREMENT**[Hand Tools](#)[Holemaking](#)[Bending](#)[Fishing](#)[Cable Pulling](#)[Wire & Cable Termination](#)[Voice Data Video](#)[Testing & Measurement](#)[Storage & Material Handling](#)[Hydraulic Pumps & Miscellaneous](#)

Name:
Pocket Multimeter

Cat #:
PDMM-20


UPC #:
11689

Spec:
Voltage measurement - 6.00, 60.00, 450.0 Resistance measurement - 600.0 ohms; 6.000, 60.00, 600.0 k Ω ; 6.000 Mohms
Capacitance - 100.0, 1000 nF; 10.00, 100.0 mF Display - 6000-count
LCD Measurement Category - CAT II, 450 V per IEC 61010-1; CAT III, 300 V

Description:

- Auto-select mode for hassle free use
- Low impedance eliminates stray or 'ghost' voltage readings.
- AC/DC voltage measurement.
- Hassle free, automatic measurement of voltage and resistance.
- Autoranging for quick, convenient measurements.
- Non-contact voltage detection for identifying live lines without contacting conductors.
- Intelligent Auto-Off for longer battery life.
- Low battery indicator.
- Resistance measurement.
- Audible continuity test.
- Frequency measurement in voltage mode.
- Capacitance measurement.
- 6000-count LCD for high resolution.

- Lifetime Limited Warranty.

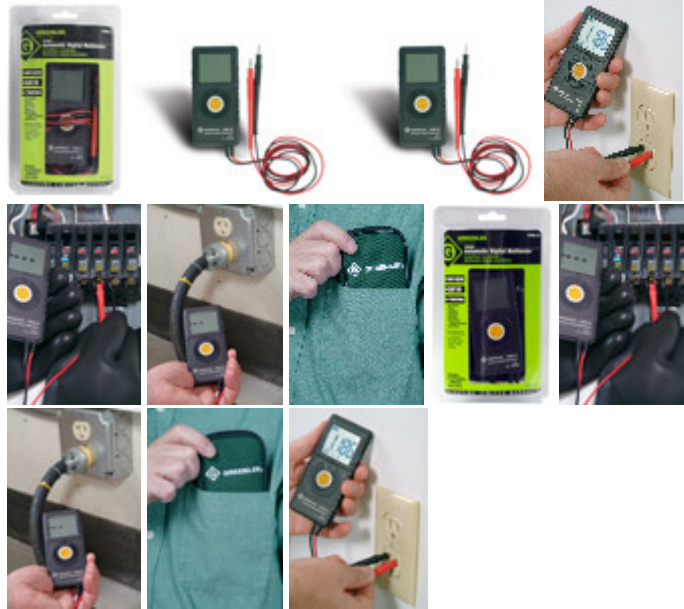

© 2007 Greenlee Textron Inc., a subsidiary of **Textron Inc.** All rights reserved.

[Privacy Policy](#) [Terms of Use](#) [Careers](#)