


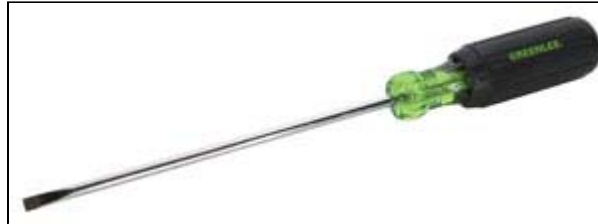

PRODUCT SEARCH

[HOME](#)[WHAT'S NEW](#)[SERVICE / SUPPORT](#)[WHERE TO BUY](#)[INSTRUCTION MANUALS](#)[CO](#)**TERMINATION**[Hand Tools](#)[Holemaking](#)[Bending](#)[Fishing](#)[Cable Pulling](#)[Wire & Cable Termination](#)[Voice Data Video](#)[Testing & Measurement](#)[Storage & Material Handling](#)[Hydraulic Pumps & Miscellaneous](#)**Name:**

Round Shank 3/16" x 6" Flat Blade Screwdriver

Cat #:

0153-22C

UPC #:

54653

Spec:

Overall Length: 9-3/4"(24.8 cm) Weight: 0.18 lbs(.08 kg)

Description:

Narrow cabinet tip for limited access applications.

- Handle marked for easy identification of screwdriver size, type, and length.
- Precision-machined tips for accurate fastener contact.
- Strong, durable black phosphate tips prevents plate chipping and reduces slipping.
- Soft, cushioned grip for extra comfort and torque.
- Exceeds ASME/ANSI specifications.
- Lifetime limited warranty.
- Note: This is not an insulated tool.

