


PAR - Plug-in CFL Lamps



Features

- Same size, same light output, same shape as halogen PAR lamps
- Weatherproof
- Indoor/outdoor use (base up)
- Instant on
- Starting temperature: -23 °C/-10 °F
-  listed

Benefits

- Direct retrofit to halogen PARs
- Saves on energy and maintenance costs

PAR20



MOL = 3 1/4 in. (95 mm)
Dia. = 2 1/2 in. (63 mm)

PAR30LN



MOL = 5 in. (127 mm)
Dia. = 3 1/4 in. (95 mm)


PAR38



MOL = 5 1/2 in. (139 mm)
Dia. = 4 13/16 in. (122 mm)

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	Halogen equivalent (W)	Case qty
59673	CF9/27K/PAR20/E26/ELUME	9	E26	2700	82	8000	300	50	48
59674	CF9/41K/PAR20/E26/ELUME	9	E26	4100	82	8000	300	50	48
59675	CF15/27K/PAR30LN/E26/ELUME	15	E26	2700	82	8000	700	75	24
59676	CF15/41K/PAR30LN/E26/ELUME	15	E26	4100	82	8000	700	75	24
59671	CF23/27K/PAR38/E26/ELUME	23	E26	2700	82	8000	1280	90	24
59672	CF23/30K/PAR38/E26/ELUME	23	E26	3000	82	8000	1280	90	24
59670	CF23/41K/PAR38/E26/ELUME	23	E26	4100	82	8000	1280	90	24

2-PIN LAMP BASES

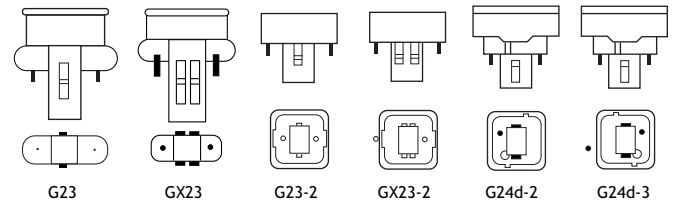

2-PIN

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL (in.) (mm)	Case qty
14105	PL5/27K/TT/2P/ELUME	5	G-23	2700	82	10000	210	4 1/8 105	96
14031	PL7/27K/TT/2P/ELUME	7	G-23	2700	82	10000	360	5 5/16 135	96
14032	PL7/41K/TT/2P/ELUME	7	G-23	4100	82	10000	360	5 5/16 135	96
14033	PL9/27K/TT/2P/ELUME	9	G-23	2700	82	10000	525	6 1/2 165	96
14034	PL9/41K/TT/2P/ELUME	9	G-23	4100	82	10000	525	6 1/2 165	96
14035	PL13/27K/TT/2P/ELUME	13	GX-23	2700	82	10000	720	7 3/32 180	96
14107	PL13/35K/TT/2P/ELUME	13	GX-23	3500	82	10000	720	7 3/32 180	96
14036	PL13/41K/TT/2P/ELUME	13	GX-23	4100	82	10000	720	7 3/32 180	96



Twin Tube