




Double
Twin Tube

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL		Case qty
								(in.)	(mm)	
14106	PL9/27K/DTT/2P/ELUME	9	G23-2	2700	82	10000	475	4 11/32	110	96
14037	PL13/27K/DTT/2P/ELUME	13	GX23-2	2700	82	10000	810	4 21/32	118	96
14108	PL13/35K/DTT/2P/ELUME	13	GX23-2	3500	82	10000	810	4 21/32	118	96
14109	PL13/41K/DTT/2P/ELUME	13	GX23-2	4100	82	10000	810	4 21/32	118	96
14111	PL18/35K/DTT/2P/ELUME	18	G24d-2	3500	82	10000	1035	5 31/32	152	96
14112	PL18/41K/DTT/2P/ELUME	18	G24d-2	4100	82	10000	1035	5 31/32	152	96
14113	PL26/27K/DTT/2P/ELUME	26	G24d-3	2700	82	10000	1540	6 13/16	173	96
14114	PL26/35K/DTT/2P/ELUME	26	G24d-3	3500	82	10000	1540	6 13/16	173	96
14115	PL26/41K/DTT/2P/ELUME	26	G24d-3	4100	82	10000	1540	6 13/16	173	96

4-PIN LAMP BASES

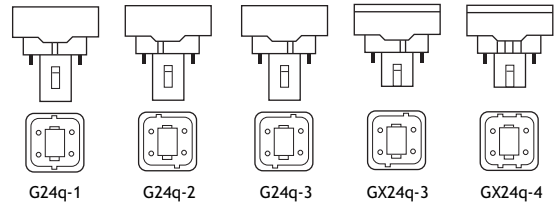

4-PIN



Double
Twin Tube

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL		Case qty
								(in.)	(mm)	
14116	PL13/27K/DTT/4P/ELUME	13	G24q-1	2700	82	10000	810	5 5/32	131	96
14117	PL13/30K/DTT/4P/ELUME	13	G24q-1	3000	82	10000	810	5 5/32	131	96
14118	PL13/35K/DTT/4P/ELUME	13	G24q-1	3500	82	10000	810	5 5/32	131	96
14119	PL13/41K/DTT/4P/ELUME	13	G24q-1	4100	82	10000	810	5 5/32	131	96
14120	PL18/30K/DTT/4P/ELUME	18	G24q-2	3000	82	10000	1035	5 25/32	147	96
14121	PL18/35K/DTT/4P/ELUME	18	G24q-2	3500	82	10000	1035	5 25/32	147	96
14122	PL18/41K/DTT/4P/ELUME	18	G24q-2	4100	82	10000	1035	5 25/32	147	96
14123	PL26/27K/DTT/4P/ELUME	26	G24q-3	2700	82	10000	1540	6 1/2	165	96
14124	PL26/30K/DTT/4P/ELUME	26	G24q-3	3000	82	10000	1540	6 1/2	165	96
14125	PL26/35K/DTT/4P/ELUME	26	G24q-3	3500	82	10000	1540	6 1/2	165	96
14126	PL26/41K/DTT/4P/ELUME	26	G24q-3	4100	82	10000	1540	6 1/2	165	96



Triple
Twin Tube

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL		Case qty
								(in.)	(mm)	
14128	PL26/35K/TTT/4P/ELUME	26	GX24q-3	3500	82	10000	1620	5 5/32	131	96
14129	PL26/41K/TTT/4P/ELUME	26	GX24q-3	4100	82	10000	1620	5 5/32	131	96
14130	PL32/30K/TTT/4P/ELUME	32	GX24q-3	3000	82	10000	2160	5 25/32	147	96
14131	PL32/35K/TTT/4P/ELUME	32	GX24q-3	3500	82	10000	2160	5 25/32	147	96
14132	PL32/41K/TTT/4P/ELUME	32	GX24q-3	4100	82	10000	2160	5 25/32	147	96
14134	PL42/35K/TTT/4P/ELUME	42	GX24q-4	3500	82	10000	2880	6 1/2	165	96
14135	PL42/41K/TTT/4P/ELUME	42	GX24q-4	4100	82	10000	2880	6 1/2	165	96