

# LED Gimbal



LED Gimbal Downlights are easy to install and allow you to direct the light where needed! The interchangeable trims offered in a variety of shapes, sizes and finishes, give you many options to choose from. Whether in new construction or in retrofit applications, the module and trim combination will fit any application!

- Small aperture designed for a sleek and glare free result
- Light output comparable to a PAR20 halogen lamp
- 24° tilt and 360° module rotation to light any direction




## LED Modules and Drivers


Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	CBCP (cd)	Finish	Traditional equivalent (W)	Case qty (master)
<b>Warm-Dim Module</b>												
65981	LED/DL/GIMBAL/MOD/7W/30-22K/WH/STD	7	120	3 000-2 200	470	≥90	30 000	40	800	White	50	18
65982	LED/DL/GIMBAL/MOD/7W/30-22K/BN/STD	7	120	3 000-2 200	470	≥90	30 000	40	800	Brushed nickel	50	18
<b>Module</b>												
65420	LED/DL/GIMBAL/MOD/7W/30K/WH/STD	7	120	3 000	600	≥80	36 000	40	1 100	White	50	18
65422	LED/DL/GIMBAL/MOD/7W/30K/BN/STD	7	120	3 000	600	≥80	36 000	40	1 100	Brushed nickel	50	18
65421	LED/DL/GIMBAL/MOD/7W/40K/WH/STD	7	120	4 000	620	≥80	36 000	40	1 200	White	50	18
65423	LED/DL/GIMBAL/MOD/7W/40K/BN/STD	7	120	4 000	620	≥80	36 000	40	1 200	Brushed nickel	50	18

## Trims


Order code	Description	Finish	Type	Case qty (master)
<b>3" Round</b>				
65432	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65433	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66230	LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BK/STD	Black	Flat	96
65450	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/WH/STD	White	Curved	96
65451	LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/BN/STD	Brushed nickel	Curved	96
<b>3" Square</b>				
65434	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65435	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66231	LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96
<b>4" Round</b>				
65436	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/WH/STD	White	Flat	96
65437	LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/BN/STD	Brushed nickel	Flat	96
66232	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96
<b>4" Square</b>				
65438	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/WH/STD	White	Flat	96
65439	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BN/STD	Brushed nickel	Flat	96
66233	LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BK/STD	Black	Flat	96

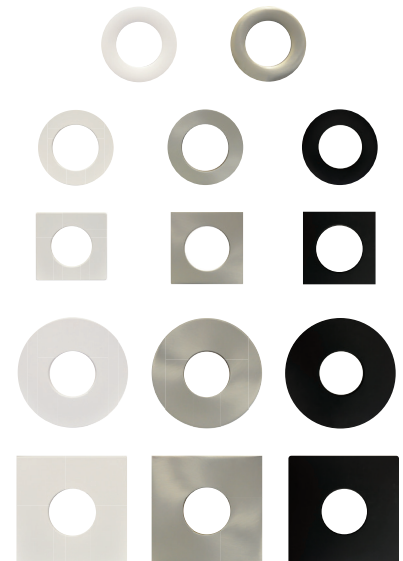

# Dimensions

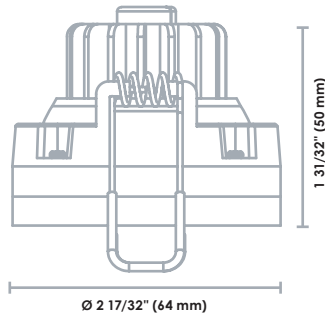


Module

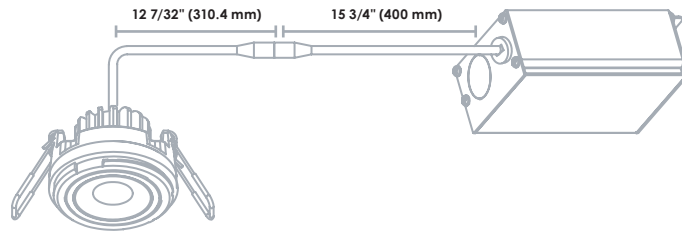


Module and Driver




Ø 2 3/4" (70 mm)

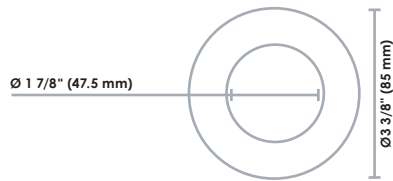


3" Trim

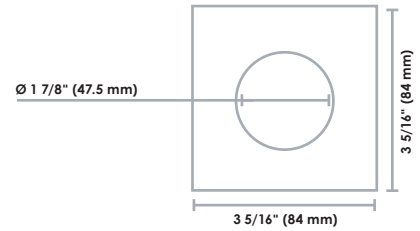


3" Trim

 

Ø 2 3/4" - 4 1/4" (70-108 mm)

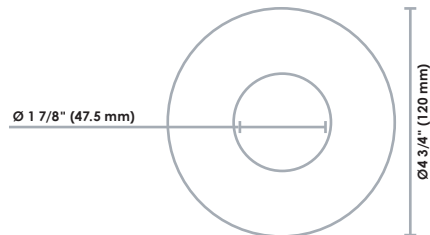


4" Trim

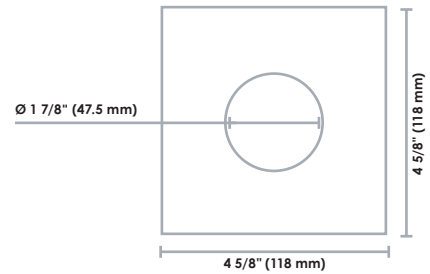

4" Trim

## Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66020	ACC/MPLATE/2.75IN/SQR/STD	2 3/4	Square mounting plate	96
66021	ACC/MPLATE/2.75IN/ADJ/STD	2 3/4	Adjustable mounting plate	24
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96

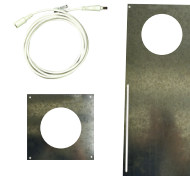

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)



AIRTIGHT



DAMP



DIMMABLE



RATED



QUICK CONNECT



WARM DIM



5 YEARS WARRANTY



Intertek



ENERGY STAR