




**STANDARD** offers a full line of premium quality, professional grade reflector halogen lamps.

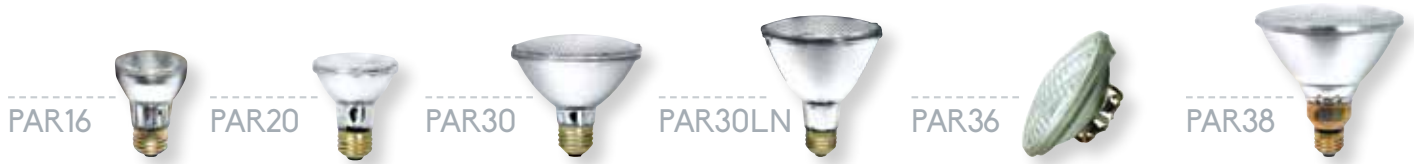

Order code	Description	Watts (W)	Base	Volts (V)	Colour temp. (K)	Beam angle (°)	Beam spread	CBCP (cd)	Average life (hrs)	Initial lumens (lm)	Case qty
<b>PAR16</b>											
MOL : 3 7/32 in. (82 mm) Dia. : 2 in. (51 mm)											
50974	H40PAR16/NFL/2.5M/130V/STD	40	E26	130	2 800	30	Narrow Flood	530	2 500	400	120
50975	H60PAR16/NFL/2.5M/130V/STD	60	E26	130	2 800	30	Narrow Flood	1 100	2 500	650	120
<b>PAR20</b>											
MOL : 3 7/32 in. (82 mm) Dia. : 2.5 in. (63.5 mm)											
51084	H35PAR20/NFL/2.5M/120V/STD	35	E26	120	2 800	30	Narrow Flood	630	2 500	315	15
51083	H35PAR20/NFL/5M/130V/STD	35	E26	130	2 800	28	Narrow Flood	630	5 000	235	15
*50738	H50PAR20/NFL/2.5M/120V/STD	50	E26	120	2 800	28	Narrow Flood	1 050	2 500	550	15
*51146	H50PAR20/NFL/5M/130V/STD	50	E26	130	2 800	28	Narrow Flood	1 050	5 000	410	15
<b>PAR30</b>											
MOL : 3 25/32 in. (93 mm) Dia. : 3 3/4 in. (95 mm)											
*10382	H50PAR30/NSP/5M/130V/STD	50	E26	130	2 800	13	Narrow Spot	5 000	5 000	495	15
*10383	H50PAR30/NFL/5M/130V/STD	50	E26	130	2 800	30	Narrow Flood	2 000	5 000	495	15
*10381	H50PAR30/FL/2.5M/120V/STD	50	E26	120	2 800	40	Flood	1 350	2 500	660	15
*50739	H50PAR30/FL/5M/130V/STD	50	E26	130	2 800	40	Flood	1 350	5 000	495	15
*50016	H75PAR30/NSP/2.5M/120V/STD	75	E26	120	2 800	10	Narrow Spot	8 000	2 500	1 100	90
*10387 <sup>1</sup>	H75PAR30/NSP/5M/130V/STD	75	E26	130	2 800	13	Narrow Spot	8 000	5 000	825	15
*10385	H75PAR30/FL/2.5M/120V/STD	75	E26	120	2 800	40	Flood	2 000	2 500	1 100	15
*50740	H75PAR30/FL/5M/130V/STD	75	E26	130	2 800	40	Flood	2 000	5 000	825	15
<b>PAR30LN</b>											
MOL : 4 13/16 in. (122 mm) Dia. : 3 3/4 in. (95 mm)											
*50229	H50PAR30/LN/NSP/2.5M/120V/STD	50	E26	120	2 800	9	Narrow Spot	5 000	2 500	660	90
*50084	H50PAR30/LN/NFL/5M/130V/STD	50	E26	130	2 800	25	Narrow Flood	2 000	5 000	495	15
*10384	H50PAR30/LN/FL/2.5M/120V/STD	50	E26	120	2 800	40	Flood	1 350	2 500	660	15
*50741	H50PAR30/LN/FL/5M/130V/STD	50	E26	130	2 800	40	Flood	1 350	5 000	495	15
*50052	H75PAR30/LN/NSP/2.5M/120V/STD	75	E26	120	2 800	9	Narrow Spot	8 000	2 500	1 100	15
*50051	H75PAR30/LN/NFL/2.5M/120V/STD	75	E26	120	2 800	25	Narrow Flood	2 400	2 500	1 100	90
*10388	H75PAR30/LN/FL/2.5M/120V/STD	75	E26	120	2 800	40	Flood	2 000	2 500	1 100	15
*50742	H75PAR30/LN/FL/5M/130V/STD	75	E26	130	2 800	40	Flood	2 000	5 000	825	15



<sup>1</sup>This product is no longer manufactured as per Energy Efficiency Regulations, note that it will remain available until stock is depleted.  
\* Cannot be sold in Ontario as per provincial regulations on energy efficiency of lighting products.

# Reflector Lamps