





03

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Case qty (master)
Single										
65838	SVAN/SINGLE/10W/30K/BN/F/STD	10	120	3 000	628	90	50 000	120	Brushed nickel	12
65839	SVAN/SINGLE/10W/40K/BN/F/STD	10	120	4 000	669	90	50 000	120	Brushed nickel	12
Double										
65840	SVAN/DOUBLE/20W/30K/BN/F/STD	20	120	3 000	1 266	90	50 000	120	Brushed nickel	12
65841	SVAN/DOUBLE/20W/40K/BN/F/STD	20	120	4 000	1 344	90	50 000	120	Brushed nickel	12
Triple										
65842	SVAN/TRIPLE/30W/30K/BN/F/STD	30	120	3 000	1 917	90	50 000	120	Brushed nickel	6
65843	SVAN/TRIPLE/30W/40K/BN/F/STD	30	120	4 000	2 023	90	50 000	120	Brushed nickel	6
Quadruple										
65844	SVAN/QUAD/40W/30K/BN/F/STD	40	120	3 000	2 579	90	50 000	120	Brushed nickel	6
65845	SVAN/QUAD/40W/40K/BN/F/STD	40	120	4 000	2 422	90	50 000	120	Brushed nickel	6

Replacement Lens

Order code	Description	Finish	Case qty (inner/master)
65959	SVAN/LENS/F/STD	Frosted	10/200

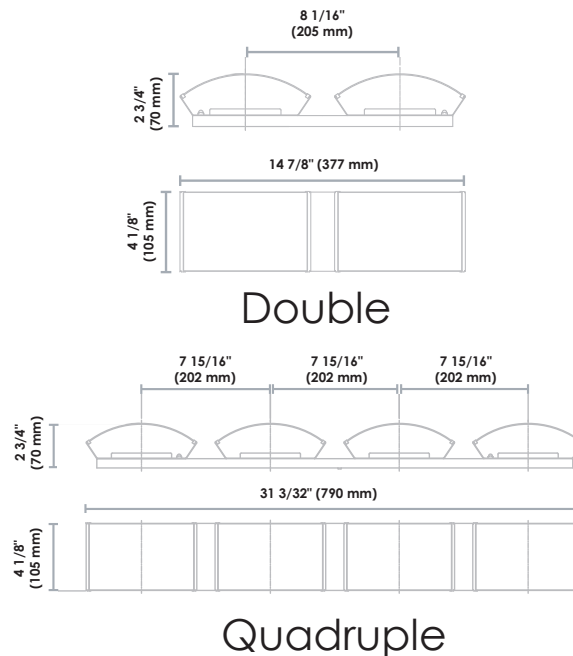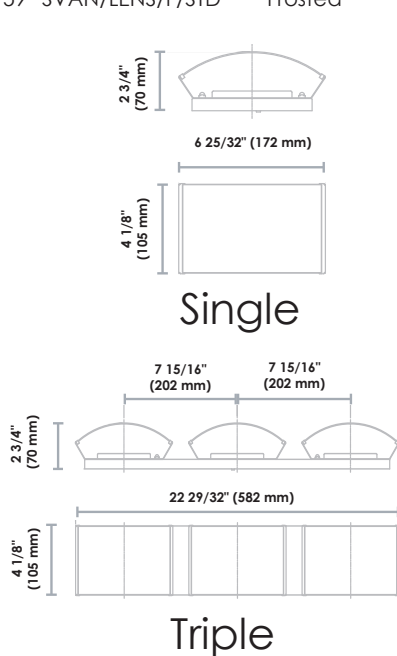

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com